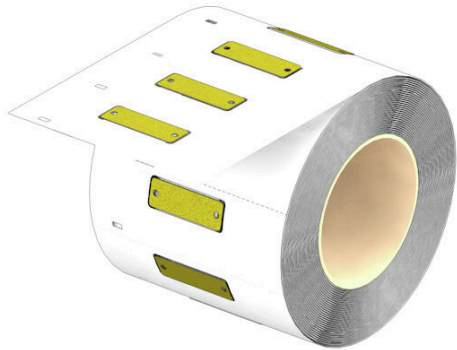


CC-M 15/45 2X3 LRP AL GE SDR

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

**General ordering data**

Version	MetalliCard, Device markers, 15 x 45 mm, silver
Order No.	2859710000
Type	CC-M 15/45 2X3 LRP AL GE SDR
GTIN (EAN)	4064675572633
Qty.	1 items
Delivery status	This article will no longer be available in the future.
Available until	2025-12-31T00:00:00+01:00

CC-M 15/45 2X3 LRP AL GE SDR

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	0.5 mm	Depth (inches)	0.0197 inch
Height	15 mm	Height (inches)	0.5906 inch
Width	45 mm	Width (inches)	1.7716 inch
Net weight	0.88 g		

Temperatures

Operating temperature range	-55...130 °C
-----------------------------	--------------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

General data

Version	pluggable, with 3.5 mm mounting hole		
Width	45 mm		
Operating temperature range, max.	130 °C		
Operating temperature range, min.	-55 °C		
Colour	silver		
Basic material	Anodized aluminium		
Printed characters	To customer specification		
Number of markers per packaging unit	Form of supply	MetalliCard	
Size of labelling field	15.2 x 42.2 mm		
compatible printer			
Number of markers per combination	1 MetalliCard = Device markers		
Operating temperature range	-55...130 °C		

Device markers

Drill-hole diameter	3.30 mm
---------------------	---------

Classifications

ETIM 8.0	EC001288	ETIM 9.0	EC001288
ETIM 10.0	EC001288	ECLASS 14.0	27-28-11-04
ECLASS 15.0	27-28-11-04		

CC-M 15/45 2X3 LRP AL GE SDR

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

