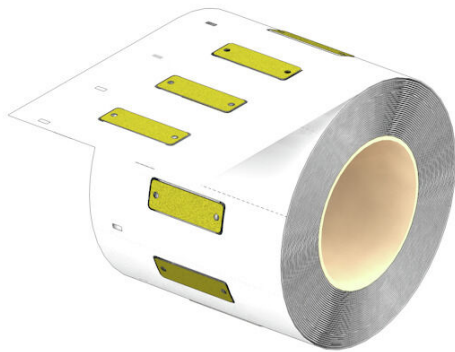


CC-M 15/45 2X3 LRP AL GE**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**General ordering data**

Version	MetalliCard, Device markers, 15 x 45 mm, silver
Order No.	2863820000
Type	CC-M 15/45 2X3 LRP AL GE
GTIN (EAN)	4064675597407
Qty.	500 items
Delivery status	This article will no longer be available in the future.
Available until	2025-06-30T00:00:00+02:00

CC-M 15/45 2X3 LRP AL GE

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Depth	0.5 mm	Depth (inches)	0.0197 inch
Height	15 mm	Height (inches)	0.5906 inch
Width	45 mm	Width (inches)	1.7716 inch
Net weight	1.86 g		

Temperatures

Operating temperature range	-55...130 °C
-----------------------------	--------------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

General data

Version	pluggable, with 3.5 mm mounting hole	
Width	45 mm	
Operating temperature range, max.	130 °C	
Operating temperature range, min.	-55 °C	
Colour	silver	
Basic material	Anodized aluminium	
Printed characters	neutral	
Number of markers per packaging unit	Form of supply	MetalliCard
Size of labelling field	15.2 x 42.2 mm	
compatible printer		
Number of markers per combination	1 MetalliCard = Device markers	
Operating temperature range	-55...130 °C	

Device markers

Drill-hole diameter	3.30 mm
---------------------	---------

Classifications

ETIM 8.0	EC001288	ETIM 9.0	EC001288
ETIM 10.0	EC001288	ECLASS 14.0	27-28-11-04
ECLASS 15.0	27-28-11-04		

Drawings

