


**WAD 12N MC SDR****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

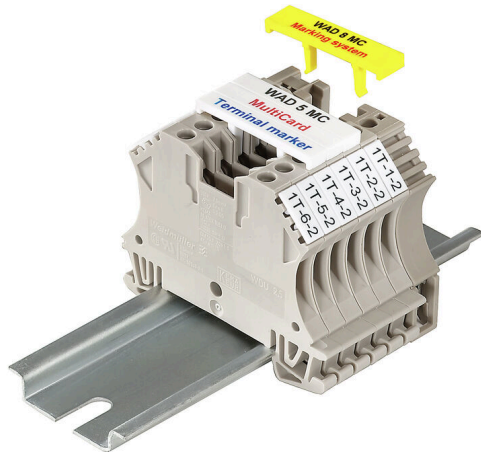

The WAD connector marker is suitable for W-series terminals and for the WEW 35/2 and ZEW 35/2 end brackets. The markers are available as blank markers, with custom printing or standard print with lightning symbol. The WAD MultiCard markers are suitable for labelling with PrintJet CONNECT printers. For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

**General ordering data**

Version	Group markers, Cover, 33.3 x 12 mm, WDU 16N
Order No.	<a href="#">2866680000</a>
Type	WAD 12N MC SDR
GTIN (EAN)	406467560489 1
Qty.	8 items

**WAD 12N MC SDR**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Approvals**

ROHS Conform

**Dimensions and weights**

Height	33.3 mm	Height (inches)	1.311 inch
Width	12 mm	Width (inches)	0.4724 inch
Net weight	1.86 g		

**Temperatures**

Operating temperature range -40...100 °C

**Environmental Product Compliance**

RoHS Compliance Status Compliant without exemption  
 REACH SVHC No SVHC above 0.1 wt%

**General data**

Orientation of print	horizontal and vertical	
Width	12 mm	
UL 94 flammability rating	V-2	
Operating temperature range, max.	100 °C	
Operating temperature range, min.	-40 °C	
Halogen	No	
Basic material	Polyamide 66	
Printed characters	To customer specification	
Number of markers per packaging unit	Form of supply	MultiCard
Number of markers per combination	1 MultiCard = Cover	
Operating temperature range	-40...100 °C	
Application/manufacture	WDU 16N	

**Classifications**

ETIM 8.0	EC000761	ETIM 9.0	EC000761
ETIM 10.0	EC000761	ECLASS 14.0	27-28-11-01
ECLASS 15.0	27-28-11-01		

**Drawings**

---

---

**Drawing**

---

---