

THM MULTIMARK LPC

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

**THM MultiMark LPC (Labeling Processing Center)**

- Fast and efficient marking of devices and operating equipment
- Laser assisted alignment
- Ergonomic operation via foot switch
- High repetition accuracy
- Controlled via Weidmüller M-Print PRO© software

General ordering data

Version	Marking systems, Thermal transfer, 300 DPI, Multi-Mark, Labels, Label reel
Order No.	2878190000
Type	THM MULTIMARK LPC
GTIN (EAN)	4064675667568
Qty.	1 items

THM MULTIMARK LPC

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	648 mm	Depth (inches)	25.5118 inch
Height	785 mm	Height (inches)	30.9054 inch
Width	466 mm	Width (inches)	18.3464 inch
Net weight	22000 g		

Environmental Product Compliance

RoHS Compliance Status	Compliant
REACH SVHC	Lead 7439-92-1

Labelling systems

Marker type	MultiMark, Labels, Label reel	System requirements	PC with operating system Windows 7, 8 or 10
Printing method	Thermal transfer	Interface	USB 2.0, Ethernet
Software	M-Print® PRO	Supply voltage	100...240 V AC
Operating system	Windows 7, Windows 8, Windows 8.1, Windows 10	Printing speed	max. 150 mm/s
Print resolution, max.	300 DPI	Operation with rechargeable batteries	No
Download	M-Print PRO	Included in delivery	USB cable, Euro plug, UK plug, US plug, Manual, RIBBON MM-TB 25/360 SW ink ribbon, DVD with M-Print® PRO, Ink ribbon core, Print roller, Applicator incl. laser unit and stamp, Mounting foot, Footswitch, Printer

Classifications

ETIM 8.0	EC000610	ETIM 9.0	EC000610
ETIM 10.0	EC000610	ECLASS 14.0	24-32-11-90
ECLASS 15.0	24-32-11-90		

THM MULTIMARK LPC

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

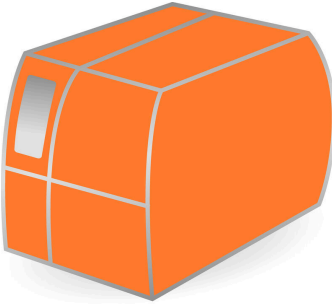
www.weidmueller.com

Accessories**Ink ribbons**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	RIBBON MM-TB 25/360 SW	Version	
Order No.	2005090000	Ink ribbon	
GTIN (EAN)	4050118390216		
Qty.	1 ST		

THM MULTIMARK PLUS

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	MULTIMARK PLUS ROLLER 1...	Version	
Order No.	2672590000		
GTIN (EAN)	4050118708097		
Qty.	1 ST		