

## THM MULTIMARK LPC

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)



### THM MultiMark LPC (Labeling Processing Center)

- Fast and efficient marking of devices and operating equipment
- Laser assisted alignment
- Ergonomic operation via foot switch
- High repetition accuracy
- Controlled via Weidmüller M-Print PRO© software

### General ordering data

Version	Marking systems, Thermal transfer, 300 DPI, Multi-Mark, Labels, Label reel
Order No.	<a href="#">2878190000</a>
Type	THM MULTIMARK LPC
GTIN (EAN)	4064675667568
Qty.	1 items

**THM MULTIMARK LPC**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Dimensions and weights**

Depth	648 mm	Depth (inches)	25.5118 inch
Height	785 mm	Height (inches)	30.9054 inch
Width	466 mm	Width (inches)	18.3464 inch
Net weight	22000 g		

**Environmental Product Compliance**

RoHS Compliance Status	Compliant
REACH SVHC	Lead 7439-92-1

**Labelling systems**

Marker type	MultiMark, Labels, Label reel	System requirements	PC with operating system Windows 7, 8 or 10
Printing method	Thermal transfer	Interface	USB 2.0, Ethernet
Software	M-Print® PRO	Supply voltage	100...240 V AC
Operating system	Windows 7, Windows 8, Windows 8.1, Windows 10	Printing speed	max. 150 mm/s
Print resolution, max.	300 DPI	Operation with rechargeable batteries	No
Included in delivery	USB cable, Euro plug, UK plug, US plug, Manual, RIBBON MM-TB 25/360 SW ink ribbon, DVD with M-Print® PRO, Ink ribbon core, Print roller, Applicator incl. laser unit and stamp, Mounting foot, Footswitch, Printer		

**Classifications**

ETIM 8.0	EC000610	ETIM 9.0	EC000610
ETIM 10.0	EC000610	ECLASS 14.0	24-32-11-90
ECLASS 15.0	24-32-11-90		

**THM MULTIMARK LPC**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

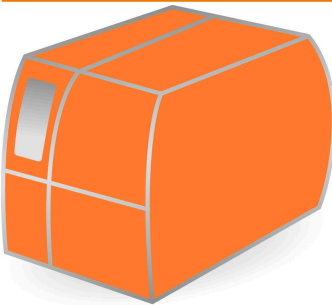
[www.weidmueller.com](http://www.weidmueller.com)

**Accessories****Ink ribbons**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

**General ordering data**

Type	RIBBON MM-TB 25/360 SW	Version	
Order No.	<a href="#">2005090000</a>	Ink ribbon	
GTIN (EAN)	4050118390216		
Qty.	1 ST		

**THM MULTIMARK PLUS**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

**General ordering data**

Type	MULTIMARK PLUS ROLLER 1...	Version	
Order No.	<a href="#">2672590000</a>		
GTIN (EAN)	4050118708097		
Qty.	1 ST		