


ESG-LP 9/20 MM WS

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

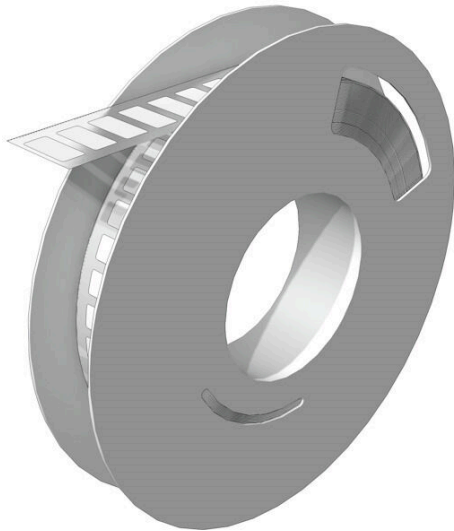

General ordering data

Version	ESG, Device markers, 9 x 20 mm, white
Order No.	2885840000
Type	ESG-LP 9/20 MM WS
GTIN (EAN)	4064675854449
Qty.	15000 items

ESG-LP 9/20 MM WS

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

ROHS Conform

Dimensions and weights

Depth	0.05 mm	Depth (inches)	0.002 inch
Height	9 mm	Height (inches)	0.3543 inch
Width	20 mm	Width (inches)	0.7874 inch
Net weight	0.01 g		

Environmental Product Compliance

RoHS Compliance Status Compliant without exemption
 REACH SVHC No SVHC above 0.1 wt%

General data

Adhesive	Acrylate adhesive	Version	Self-adhesive, halogen-free
Width	20 mm	UL 94 flammability rating	V-0
Operating temperature range, max.	150 °C	Operating temperature range, min.	-40 °C
Colour	white	Halogen	No
Basic material	Polyamide	Printed characters	without
Approval acc. to UL 969	Yes		

Device markers

Halogen No

Classifications

ETIM 8.0	EC001288	ETIM 9.0	EC001288
ETIM 10.0	EC001288	ECLASS 14.0	27-28-11-04
ECLASS 15.0	27-28-11-04		

Drawings

