


ESG-LP 9/20 MM GE

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

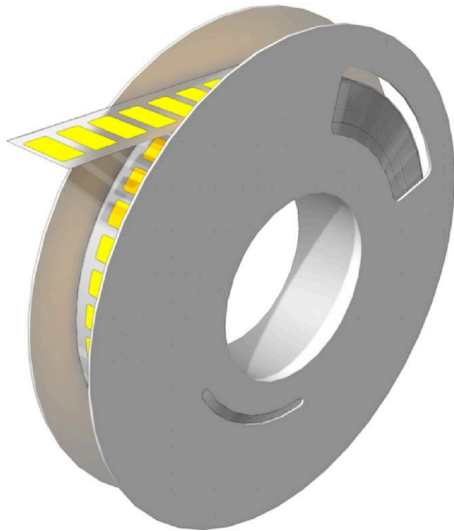

General ordering data

Version	ESG, Device markers, 9 x 20 mm, yellow
Order No.	2885850000
Type	ESG-LP 9/20 MM GE
GTIN (EAN)	4064675854456
Qty.	15000 items

ESG-LP 9/20 MM GE

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Depth	0.05 mm	Depth (inches)	0.002 inch
Height	9 mm	Height (inches)	0.3543 inch
Width	20 mm	Width (inches)	0.7874 inch
Net weight	0.01 g		

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

General data

Adhesive	Acrylate adhesive	Version	Self-adhesive, halogen-free
Width	20 mm	UL 94 flammability rating	V-0
Operating temperature range, max.	150 °C	Operating temperature range, min.	-40 °C
Colour	yellow	Halogen	No
Basic material	Polyamide	Printed characters	without
Approval acc. to UL 969	Yes		

Device markers

Halogen	No
---------	----

Classifications

ETIM 6.0	EC001288	ETIM 7.0	EC001288
ETIM 8.0	EC001288	ETIM 9.0	EC001288
ETIM 10.0	EC001288	ECLASS 9.0	27-40-06-29
ECLASS 9.1	27-40-06-29	ECLASS 10.0	27-40-06-29
ECLASS 11.0	27-28-11-04	ECLASS 12.0	27-28-11-04
ECLASS 13.0	27-28-11-04	ECLASS 14.0	27-28-11-04
ECLASS 15.0	27-28-11-04		

Drawings

