


**ESG-LP 9/20 MM GE**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

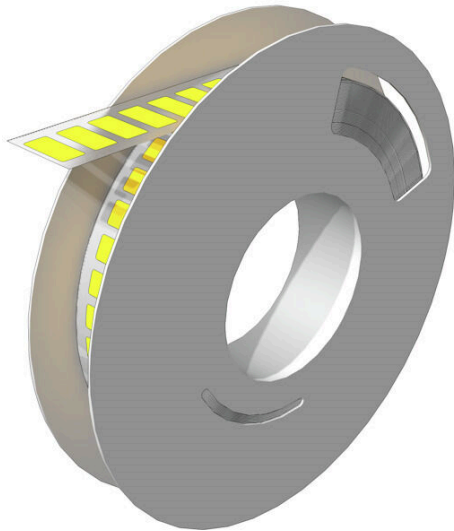

**General ordering data**

Version	ESG, Device markers, 9 x 20 mm, yellow
Order No.	<a href="#">2885850000</a>
Type	ESG-LP 9/20 MM GE
GTIN (EAN)	4064675854456
Qty.	15000 items

**ESG-LP 9/20 MM GE**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Approvals**

ROHS Conform

**Dimensions and weights**

Depth	0.05 mm	Depth (inches)	0.002 inch
Height	9 mm	Height (inches)	0.3543 inch
Width	20 mm	Width (inches)	0.7874 inch
Net weight	0.01 g		

**Environmental Product Compliance**

RoHS Compliance Status Compliant without exemption  
 REACH SVHC No SVHC above 0.1 wt%

**General data**

Adhesive	Acrylate adhesive	Version	Self-adhesive, halogen-free
Width	20 mm	UL 94 flammability rating	V-0
Operating temperature range, max.	150 °C	Operating temperature range, min.	-40 °C
Colour	yellow	Halogen	No
Basic material	Polyamide	Printed characters	without
Approval acc. to UL 969	Yes		

**Device markers**

Halogen No

**Classifications**

ETIM 8.0	EC001288	ETIM 9.0	EC001288
ETIM 10.0	EC001288	ECLASS 14.0	27-28-11-04
ECLASS 15.0	27-28-11-04		

**Drawings**

