


**ESG-LP 10/20 MM SI**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

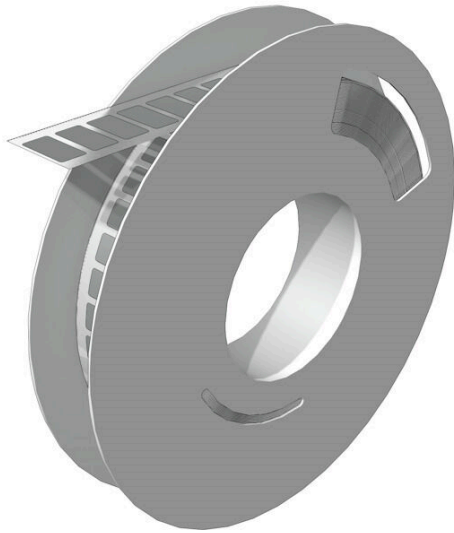

**General ordering data**

Version	ESG, Device markers, 10 x 20 mm, silver
Order No.	<a href="#">2885890000</a>
Type	ESG-LP 10/20 MM SI
GTIN (EAN)	4064675854494
Qty.	15000 items

## ESG-LP 10/20 MM SI

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Technical data

### Approvals

ROHS	Conform
------	---------

### Dimensions and weights

Depth	0.05 mm	Depth (inches)	0.002 inch
Height	10 mm	Height (inches)	0.3937 inch
Width	20 mm	Width (inches)	0.7874 inch
Net weight	0.01 g		

### Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

### General data

Adhesive	Acrylate adhesive	Version	Self-adhesive, halogen-free
Width	20 mm	UL 94 flammability rating	V-0
Operating temperature range, max.	150 °C	Operating temperature range, min.	-40 °C
Colour	silver	Halogen	No
Basic material	Polyamide	Printed characters	without
Approval acc. to UL 969	Yes		

### Device markers

Halogen	No
---------	----

### Classifications

ETIM 8.0	EC001288	ETIM 9.0	EC001288
ETIM 10.0	EC001288	ECLASS 14.0	27-28-11-04
ECLASS 15.0	27-28-11-04		

**Drawings**

