

WEP 2C 4 BL


Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

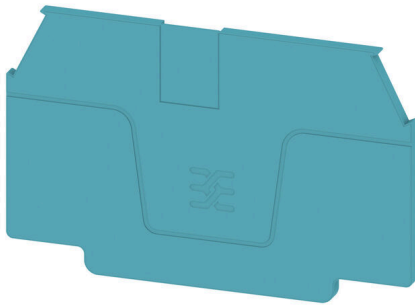

The comprehensive accessories of the Klippon® Connect portfolio are perfectly matched down to the last detail. This facilitates mounting while adhering to required norms

General ordering data

| | |
|------------|---|
| Version | End plate for terminals, blue, Height: 60 mm, Width: 2 mm, V-0, Wemid, Snap-on: Yes |
| Order No. | 2894220000 |
| Type | WEP 2C 4 BL |
| GTIN (EAN) | 4064675885207 |
| Qty. | 20 items |

WEP 2C 4 BL

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

| | |
|------|---------|
| ROHS | Conform |
|------|---------|

Dimensions and weights

| | | | |
|------------|--------|-----------------|-------------|
| Depth | 39 mm | Depth (inches) | 1.5354 inch |
| Height | 60 mm | Height (inches) | 2.3622 inch |
| Width | 2 mm | Width (inches) | 0.0787 inch |
| Net weight | 2.31 g | | |

Temperatures

| | | | |
|----------------------------------|----------------|----------------------------------|--------|
| Ambient temperature | -60 °C...85 °C | Continuous operating temp., min. | -60 °C |
| Continuous operating temp., max. | 130 °C | | |

Environmental Product Compliance

| | |
|------------------------|-----------------------------|
| RoHS Compliance Status | Compliant without exemption |
| REACH SVHC | No SVHC above 0.1 wt% |

Material data

| | | | |
|---------------------------|-------|--------|------|
| Basic material | Wemid | Colour | blue |
| UL 94 flammability rating | V-0 | | |

Additional technical data

| | |
|---------|-----|
| Snap-on | Yes |
|---------|-----|

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 8.0 | EC000886 | ETIM 9.0 | EC000886 |
| ETIM 10.0 | EC000886 | ECLASS 14.0 | 27-25-03-01 |
| ECLASS 15.0 | 27-25-03-01 | | |