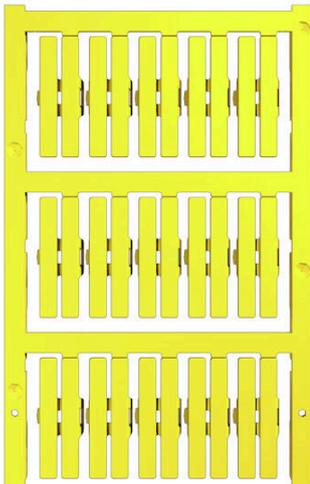


**SFC-DS 1/30 MC NE GE****Weidmüller Interface GmbH & Co. KG**Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

**SFC – SlimFix Clip MultiCard with two labelling fields**

For conductor markers, it is often required to quickly read the start and destination designation of the respective conductor. Here it makes sense to print both data directly on a marker.

The new SFC-DS markers are designed as MultiCards and are suitable for direct printing with our PrintJet printing system. Their two labelling areas allow multiple data to be printed on a single marker. The print data can be imported directly from CAE projects into the M-Print® PRO marking software. After printing, the markers are placed around the conductor and securely fixed with a special locking mechanism.

**General ordering data**

|            |  |
|------------|--|
| Version    | Conductor and cable markers, 30 x 5.2 mm, yellow |
| Order No.  | <a href="#">2905080000</a>                       |
| Type       | SFC-DS 1/30 MC NE GE                             |
| GTIN (EAN) | 4099986918665                                    |
| Qty.       | 150 items  |

## SFC-DS 1/30 MC NE GE

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Technical data

### Dimensions and weights

|            |        |                 |             |
|------------|--------|-----------------|-------------|
| Depth      | 4 mm   | Depth (inches)  | 0.1575 inch |
| Height     | 30 mm  | Height (inches) | 1.1811 inch |
| Width      | 5.2 mm | Width (inches)  | 0.2047 inch |
| Net weight | 0.44 g |                 |             |

### Environmental Product Compliance

|                          |                             |                  |  |
|--------------------------|-----------------------------|------------------|--|
| RoHS Compliance Status   | Compliant without exemption |                  |  |
| REACH SVHC               | No SVHC above 0.1 wt%       |                  |  |
| Product Carbon Footprint | Cradle to gate              | 0.004 kg CO2 eq. |  |

### General data

|                                   |              |                                   |                   |
|-----------------------------------|--------------|-----------------------------------|-------------------|
| Type of printing                  | neutral      | Version                           | with snap-in foot |
| Width                             | 5.2 mm       | UL 94 flammability rating         | V-2, UL 94        |
| Operating temperature range, max. | 100 °C       | Operating temperature range, min. | -40 °C            |
| Colour                            | yellow       | Halogen                           | No                |
| Basic material                    | Polyamide 66 | Printed characters                | without           |
| Size of labelling field           | 29 x 3.2 mm  | Number per roll                   | 30                |

### Conductor and cable markers

|                                  |                     |                               |                     |
|----------------------------------|---------------------|-------------------------------|---------------------|
| Halogen                          | No                  | Conductor cross-section, max. | 2.5 mm <sup>2</sup> |
| Conductor O.D., max.             | 3.3 mm              | Conductor O.D., min.          | 2 mm                |
| Cross-section for connected wire | 2.5 mm <sup>2</sup> |                               |                     |

### Classifications

|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 8.0    | EC001530    | ETIM 9.0    | EC001530    |
| ETIM 10.0   | EC001530    | ECLASS 14.0 | 27-28-11-02 |
| ECLASS 15.0 | 27-28-11-02 |             |             |

**SFC-DS 1/30 MC NE GE**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

**Drawings**

[www.weidmueller.com](http://www.weidmueller.com)

