

WBC-P-8OR-35**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com



Battery storage systems are playing an increasingly important role in the field of renewable energies. They usually consist of several individual batteries that need to be quick and easy to replace. The Weidmüller Battery Connector (WBC) makes it possible to connect several individual batteries to an ESS in just a few simple steps – and to disconnect the connections just as quickly if required. For more safety and easy handling, the poles are clearly marked: The positive pole in orange and the negative pole in black.

General ordering data

Order No.	2905360000
Type	WBC-P-8OR-35
GTIN (EAN)	4099986026025
Qty.	5 items
Delivery status	This article will no longer be available in the future.
Last order date	2026-09-29T00:00:00+02:00

WBC-P-8OR-35

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS Conform

UL File Number Search [UL Website](#)

Certificate No. (UR) E529699

Dimensions and weights

Net weight 46 g

Temperatures

Continuous operating temp., min. -40 °C Continuous operating temp., max. 125 °C

Humidity ≤85% RH

Environmental Product Compliance

RoHS Compliance Status Compliant without exemption

REACH SVHC No SVHC above 0.1 wt%

General Data

Outer cable diameter, max. 11.3 mm Outer cable diameter, min. 10.6 mm

Contact diameter, male Ø 8 mm Approvals UL 4128

Type of connection Crimp connection Colour orange

Conductor cross-section, max. 35 mm² Surface finish silver

Type Female Basic material PA 66

Technical Data

Vibration resistance 30g UL 94 flammability rating V-0

Volume resistance ≥ 5000 MΩ Nominal voltage 1500 V

Nominal current 150 A Protection degree IP67 plugged

Plugging cycles ≥ 100 Surge voltage category II

Operating altitude ≤ 2000 m Shock resistance V2



Classifications

ETIM 8.0 EC001121 ETIM 9.0 EC001121

ETIM 10.0 EC001121 ECLASS 14.0 27-44-03-12

ECLASS 15.0 27-44-03-12

Drawings

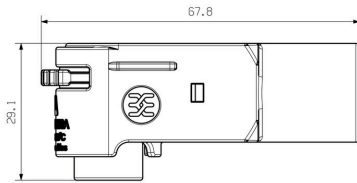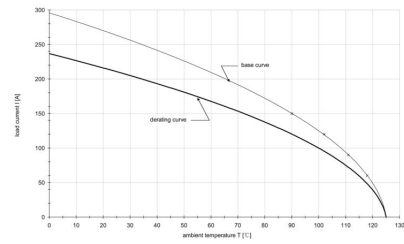

WBC-P-8OR-35

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Tools




Crimping tools for cable lugs, connectors and wire-end ferrules with interchangeable inserts

- extremely fast processing thanks to hydraulic support
- large processing range up to 300 mm²
- 270° revolving quick-action crimping head
- automatic pressure limitation and monitoring via pressure sensor
- electronic control and monitoring of the crimping process
- Saving of all crimping cycles and error messages to internal memory
- Reading of all cycles and error messages via USB
- Li-ion rechargeable battery with charge status indicator: 18 V, 2 Ah

General ordering data

Type	EPG 45	Version
Order No.	1500830000	Pressing tool, 6mm ² , 150mm ² , Hexagonal crimp, WM crimp, Indent
GTIN (EAN)	4050118309317	crimp, Trapezoidal crimp, Oval crimping
Qty.	1 ST	

... for crimp cable lugs (acc. to DIN 46234)

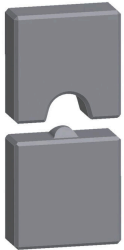

Crimping tools for cable lugs, connectors and wire-end ferrules with interchangeable inserts

- extremely fast processing thanks to hydraulic support
- large processing range up to 300 mm²
- 270° revolving quick-action crimping head
- automatic pressure limitation and monitoring via pressure sensor
- electronic control and monitoring of the crimping process
- Saving of all crimping cycles and error messages to internal memory
- Reading of all cycles and error messages via USB
- Li-ion rechargeable battery with charge status indicator: 18 V, 2 Ah

General ordering data

Type	ES EPG 45 DIN 35	Version
Order No.	1501350000	35mm ² , Indent crimp
GTIN (EAN)	4050118309645	
Qty.	1 ST	