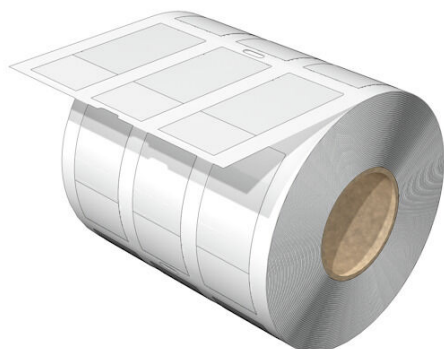


THM WO VIN 25.4/63 WS**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

THM WriteOn cable markers on reels are used for labelling conductors and cables with an outside diameter of up to 36 mm. The transparent adhesive strip fixes and protects the printing on the marker surface.

- Protection of the marking against dirt and abrasion by wrapping it with the transparent adhesive strip
- Simple and quick printing with the high-quality thermal transfer printers

General ordering data

Order No.	2912620000
Type	THM WO VIN 25.4/63 WS
GTIN (EAN)	4099986536791
Qty.	1500 items
Delivery status	This article will no longer be available in the future.
Last order date	2026-08-14T00:00:00+02:00
Alternative product	THM WO VIN 25.4/63.5 WS

THM WO VIN 25.4/63 WS

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Depth	0.03 mm	Depth (inches)	0.0012 inch
Height	25.4 mm	Height (inches)	1 inch
Width	63.5 mm	Width (inches)	2.5 inch
Net weight	0.38 g		

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

General data

Type of printing	neutral	Width	63.5 mm
UL 94 flammability rating	V-0	Operating temperature range, max.	150 °C
Operating temperature range, min.	-40 °C	Colour	white
Halogen	No	Basic material	Polyester film
Printed characters	without	Number per roll	1500

Conductor and cable markers

Halogen	No	Conductor cross-section, max.	113 mm ²
Conductor O.D., max.	12 mm	Conductor O.D., min.	8 mm

Classifications

ETIM 8.0	EC001530	ETIM 9.0	EC001530
ETIM 10.0	EC001530	ECLASS 14.0	27-28-11-02
ECLASS 15.0	27-28-11-02		