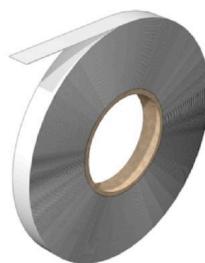


**EL KSM 8.8 MM WS 30M**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergsstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

**MultiMark MultiFit**

For connectors from competitors.

The elastic surface finish makes for simple installation.

This special material enables the strips to be stretched to accommodate slight variations in spacing, especially with long terminal blocks.

A print resolution of 300 dpi also produces a very legible script. Your benefits with MultiMark

- Firm hold and durable printing
- Continuous strips save installation time
- Easy mounting thanks to an innovative composite material
- Large label field for optimal legibility
- High flexibility thanks to manufacturer independence
- Firm hold and durable printing
- Continuous strips save installation time
- Easy mounting thanks to an innovative composite material
- Large label field for optimal legibility
- High flexibility thanks to manufacturer independence

]

- Firm hold and durable printing
- Continuous strips save installation time
- Easy mounting thanks to an innovative composite material
- Large label field for optimal legibility
- High flexibility thanks to manufacturer independence

**General ordering data**

Version	Terminal marker, 8.8 x , Pitch in mm (P): 8.80 white
Order No.	<a href="#">2922670000</a>
Type	EL KSM 8.8 MM WS 30M
GTIN (EAN)	4099986618275
Qty.	1 items

## EL KSM 8.8 MM WS 30M

Weidmüller Interface GmbH & Co. KG  
Klingenbergsstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Technical data

## Approvals

RoHS	Conform
------	---------

## Dimensions and weights

Depth	0.25 mm	Depth (inches)	0.0098 inch
Height	8.8 mm	Height (inches)	0.3465 inch
Length	30 m	Length (inches)	1181.1024 inch
Net weight	92.4 g		

## Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

## General data

Orientation of print	horizontal and vertical	Type of printing	neutral
Printing method	Thermal transfer	UL 94 flammability rating	V-2
Operating temperature range, max.	90 °C	Operating temperature range, min.	-50 °C
Colour	white	Halogen	No
Length	30 m	Basic material	Polypropylene
Printed characters	without		

## Connector markers

Pitch in mm (P)	8.80 mm
-----------------	---------

## Classifications


ETIM 8.0	EC000761	ETIM 9.0	EC000761
ETIM 10.0	EC000761	ECLASS 14.0	27-28-11-01
ECLASS 15.0	27-28-11-01		

**EL KSM 8.8 MM WS 30M**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergsstraße 26  
D-32758 Detmold  
Germany

**Drawings**

[www.weidmueller.com](http://www.weidmueller.com)

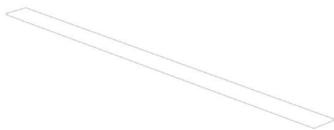

**EL KSM 8.8 MM WS 30M**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergsstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

**Accessories****Ink ribbons**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

**General ordering data**

Type	RIBBON MM-TB 25/360 SW	Version
Order No.	<a href="#">2005090000</a>	Ink ribbon
GTIN (EAN)	4050118390216	
Qty.	1 ST	