

V-ZPA FUSE HOLDER E

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com



General ordering data

Order No.	3038720000
Type	V-ZPA FUSE HOLDER E
GTIN (EAN)	4099987006422
Qty.	1 items
Delivery status	This article will no longer be available in the future.
Last order date	2025-04-23T00:00:00+02:00

V-ZPA FUSE HOLDER E

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Depth	65.5 mm	Depth (inches)	2.5787 inch
Height	92.2 mm	Height (inches)	3.6299 inch
Width	18.5 mm	Width (inches)	0.7283 inch
Net weight	74 g		

Temperatures

Storage temperature		Operating temperature	-25 °C...55 °C
Humidity	5 - 95% rel. humidity		

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

General data

Optical function display	No	Design	Adapter plug
Colour	grey	Protection degree	IP00
Mounting rail	Busbar	Acoustic signal	No
Operating altitude	≤ 4000 m		

Insulation coordination acc. to EN 50178

Pollution severity	2
--------------------	---

Rated data IEC / EN

Signalling contact	No	Rated voltage (AC)	240 V
Rated current IN	6.3 A	Voltage type	AC
Fuse protection	6.3 A	Standards	IEC 61984
Acoustic signal	No	Short-circuit current rating ISCCR	25 kA
Integrated back-up fuse	Yes		

Connection data

Stripping length	13 mm	Wire connection method	PUSH IN
Type of connection	Screw connection	Clamping range, rated connection	2.5 mm ²
Clamping range, min.	0.82 mm ²	Clamping range, max.	2.5 mm ²
Wire cross-section, solid, min.	0.82 mm ²	Wire cross-section, solid, max.	2.5 mm ²
Wire connection cross section, finely stranded, min.	0.82 mm ²	Wire connection cross section, finely stranded, max.	2.5 mm ²
Conductor cross-section, flexible, AEH (DIN 46228-1), min.	0.82 mm ²	Conductor cross-section, flexible, AEH (DIN 46228-1), max.	2.5 mm ²
Connection cross-section, stranded, min.	0.82 mm ²	Connection cross-section, stranded, max.	2.5 mm ²

Electrical data

Voltage type	AC
--------------	----

V-ZPA FUSE HOLDER E

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Technical data**General data**

Protection degree	IP00	Colour	grey
-------------------	------	--------	------

Classifications

ETIM 8.0	EC002496	ETIM 9.0	EC002496
ETIM 10.0	EC002496	ECLASS 14.0	27-17-12-92
ECLASS 15.0	27-17-12-92		

V-ZPA FUSE HOLDER E

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Accessories

Visualization and Communication cable




Base counter, gateway, control box and overvoltage protection device are connected with pre-assembled cable sets as point-to-point or Y-assembly. Weidmüller offers the right connection solutions for this, conforming to FNN and DIN-VDE 0603 standards. Pre-assembled power cables with 6kV overvoltage protection round up the portfolio.

General ordering data

Type	CH-SMC-00.80-VC180	Version	
Order No.	2775880080	Smart Metering Cable Assemblies, 6 kV, Pin, IP20, 600 V, KB PUR US	
GTIN (EAN)	4064675329909	2X1.5 GY XX 6KV, 0.8 m	
Qty.	10 ST		

Counter and Gateway cable

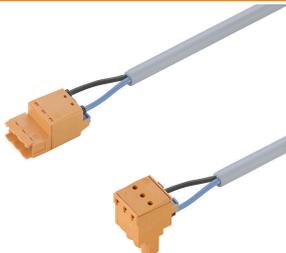

Base counter, gateway, control box and overvoltage protection device are connected with pre-assembled cable sets as point-to-point or Y-assembly. Weidmüller offers the right connection solutions for this, conforming to FNN and DIN-VDE 0603 standards. Pre-assembled power cables with 6kV overvoltage protection round up the portfolio.

General ordering data

Type	CH-SMC-00.80-CG90	Version	
Order No.	2775910080	Smart Metering Cable Assemblies, 6 kV, Socket connector, IP20, 600 V, KB PUR US	
GTIN (EAN)	4064675329732	2X1.5 GY XX 6KV, 0.8 m	
Qty.	10 ST		

Extension cable for Smart Meter



Base counter, gateway, control box and overvoltage protection device are connected with pre-assembled cable sets as point-to-point or Y-assembly. Weidmüller offers the right connection solutions for this, conforming to FNN and DIN-VDE 0603 standards. Pre-assembled power cables with 6kV overvoltage protection round up the portfolio.

General ordering data

Type	CH-SMC-00.80-ECS180	Version	
Order No.	2784120080	Smart Metering Cable Assemblies, 6 kV, Pin, IP20, 600 V, KB PUR US	
GTIN (EAN)	4064675329718	2X1.5 GY XX 6KV, 0.8 m	
Qty.	10 ST		

V-ZPA FUSE HOLDER E

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Accessories

Type	CH-SMC-00.60-ECB180	Version	
Order No.	2784110060	Smart Metering Cable Assemblies, 6 kV, Socket connector, IP20, 600	
GTIN (EAN)	4099986979093	V, KB PUR US 2X1.5 GY XX 6KV, 0.6 m	
Qty.	10 ST		

Visualization and Communication cable



Base counter, gateway, control box and overvoltage protection device are connected with pre-assembled cable sets as point-to-point or Y-assembly. Weidmüller offers the right connection solutions for this, conforming to FNN and DIN-VDE 0603 standards. Pre-assembled power cables with 6kV overvoltage protection round up the portfolio.

General ordering data

Type	CH-SMC-00.80-OVP180	Version	
Order No.	2853620080	Smart Metering Cable Assemblies, 6 kV, Pin, Socket connector, IP20,	
GTIN (EAN)	4064675477549	600 V, KB PUR US 2X1.5 GY XX 6KV, 0.8 m	
Qty.	10 ST		

Extension cable for Smart Meter



Base counter, gateway, control box and overvoltage protection device are connected with pre-assembled cable sets as point-to-point or Y-assembly. Weidmüller offers the right connection solutions for this, conforming to FNN and DIN-VDE 0603 standards. Pre-assembled power cables with 6kV overvoltage protection round up the portfolio.

General ordering data

Type	CH-SMC-01.15-ECB180	Version	
Order No.	2784110115	Smart Metering Cable Assemblies, 6 kV, Socket connector, IP20, 600	
GTIN (EAN)	4099986979208	V, KB PUR US 2X1.5 GY XX 6KV, 1.15 m	
Qty.	10 ST		

V-ZPA FUSE HOLDER E

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Visualization and Communication cable



Base counter, gateway, control box and overvoltage protection device are connected with pre-assembled cable sets as point-to-point or Y-assembly. Weidmüller offers the right connection solutions for this, conforming to FNN and DIN-VDE 0603 standards. Pre-assembled power cables with 6kV overvoltage protection round up the portfolio.

General ordering data

Type	CH-SMC-00.60-OVP180	Version	
Order No.	2853620060	Smart Metering Cable Assemblies, 6 kV, Pin, Socket connector, Pin	
GTIN (EAN)	4099986979079	connector, IP20, 600 V, KB PUR US 2X1.5 GY XX 6KV, 0.6 m	
Qty.	10 ST		

Extension cable for Smart Meter



Base counter, gateway, control box and overvoltage protection device are connected with pre-assembled cable sets as point-to-point or Y-assembly. Weidmüller offers the right connection solutions for this, conforming to FNN and DIN-VDE 0603 standards. Pre-assembled power cables with 6kV overvoltage protection round up the portfolio.

General ordering data

Type	CH-SMC-00.60-ECB90	Version	
Order No.	2817650060	Smart Metering Cable Assemblies, 6 kV, Socket connector, IP20, 600	
GTIN (EAN)	4064675323051	V, KB PUR US 2X1.5 GY XX 6KV, 0.6 m	
Qty.	10 ST		
Type	CH-SMC-00.80-ECB90	Version	
Order No.	2817650080	Smart Metering Cable Assemblies, 6 kV, Socket connector, IP20, 600	
GTIN (EAN)	4064675323068	V, KB PUR US 2X1.5 GY XX 6KV, 0.8 m	
Qty.	10 ST		
Type	CH-SMC-00.95-ECB90	Version	
Order No.	2817650095	Smart Metering Cable Assemblies, 6 kV, Socket connector, IP20, 600	
GTIN (EAN)	4064675323075	V, KB PUR US 2X1.5 GY XX 6KV, 0.95 m	
Qty.	10 ST		
Type	CH-SMC-01.20-ECB90	Version	
Order No.	2817650120	Smart Metering Cable Assemblies, 6 kV, Socket connector, IP20, 600	
GTIN (EAN)	4064675323082	V, KB PUR US 2X1.5 GY XX 6KV, 1.2 m	
Qty.	10 ST		


V-ZPA FUSE HOLDER E

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

Accessories

www.weidmueller.com

Cables

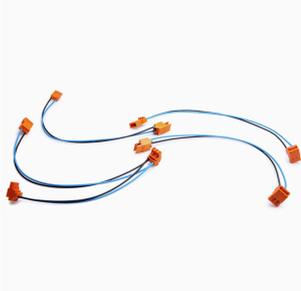

Base counter, gateway, control box and overvoltage protection device are connected with pre-assembled cable sets as point-to-point or Y-assembly. Weidmüller offers the right connection solutions for this, conforming to FNN and DIN-VDE 0603 standards. Pre-assembled power cables with 6kV overvoltage protection round up the portfolio.

General ordering data

Type	CH-SMR-00.33-VC180 VPE10	Version
Order No.	2924830033	Smart Metering Cable Assemblies, 6 kV, IP30, in plugged and mounted condition, 300 V, Li9YH 1 x 0,75, 0.33 m
GTIN (EAN)	4099986795570	
Qty.	10 ST	
Type	CH-SMR-00.80-VC180 VPE10	Version
Order No.	2924830080	Smart Metering Cable Assemblies, 6 kV, IP30, in plugged and mounted condition, 300 V, Li9YH 1 x 0,75, 0.8 m
GTIN (EAN)	4099986795587	
Qty.	10 ST	
Type	CH-SMR-00.33-CG90 VPE10	Version
Order No.	2924780033	Smart Metering Cable Assemblies, 6 kV, IP30, in plugged and mounted condition, 300 V, Li9YH 1 x 0,75, 0.33 m
GTIN (EAN)	4099986795594	
Qty.	10 ST	
Type	CH-SMR-00.80-CG90 VPE10	Version
Order No.	2924780080	Smart Metering Cable Assemblies, 6 kV, IP30, in plugged and mounted condition, 300 V, Li9YH 1 x 0,75, 0.8 m
GTIN (EAN)	4099986795600	
Qty.	10 ST	
Type	CH-SMR-00.33-ECS180 VPE...	Version
Order No.	2924850033	Smart Metering Cable Assemblies, 6 kV, IP30, in plugged and mounted condition, 300 V, Li9YH 1 x 0,75, 0.33 m
GTIN (EAN)	4099986795723	
Qty.	10 ST	
Type	CH-SMR-00.80-ECS180 VPE...	Version
Order No.	2924850080	Smart Metering Cable Assemblies, 6 kV, IP30, in plugged and mounted condition, 300 V, Li9YH 1 x 0,75, 0.8 m
GTIN (EAN)	4099986795730	
Qty.	10 ST	
Type	CH-SMR-00.33-ECB180 VPE...	Version
Order No.	2924870033	Smart Metering Cable Assemblies, 6 kV, IP30, in plugged and mounted condition, 300 V, Li9YH 1 x 0,75, 0.33 m
GTIN (EAN)	4099986795655	
Qty.	10 ST	
Type	CH-SMR-00.80-ECB180 VPE...	Version
Order No.	2924870080	Smart Metering Cable Assemblies, 6 kV, IP30, in plugged and mounted condition, 300 V, Li9YH 1 x 0,75, 0.8 m
GTIN (EAN)	4099986795662	
Qty.	10 ST	
Type	CH-SMR-00.33-ECB90 VPE10	Version
Order No.	2924890033	Smart Metering Cable Assemblies, 6 kV, IP30, in plugged and mounted condition, 300 V, Li9YH 1 x 0,75, 0.33 m
GTIN (EAN)	4099986795679	
Qty.	10 ST	
Type	CH-SMR-00.60-ECB90 VPE10	Version
Order No.	2924890060	Smart Metering Cable Assemblies, 6 kV, IP30, in plugged and mounted condition, 300 V, Li9YH 1 x 0,75, 0.6 m
GTIN (EAN)	4099986795686	
Qty.	10 ST	

V-ZPA FUSE HOLDER E

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Type	CH-SMR-00.80-ECB90 VPE10	Version
Order No.	2924890080	Smart Metering Cable Assemblies, 6 kV, IP30, in plugged and mounted condition, 300 V, Li9YH 1 x 0,75, 0.8 m
GTIN (EAN)	4099986795693	
Qty.	10 ST	
Type	CH-SMR-00.95-ECB90 VPE10	Version
Order No.	2924890095	Smart Metering Cable Assemblies, 6 kV, IP30, in plugged and mounted condition, 300 V, Li9YH 1 x 0,75, 0.95 m
GTIN (EAN)	4099986795709	
Qty.	10 ST	
Type	CH-SMR-01.20-ECB90 VPE10	Version
Order No.	2924890120	Smart Metering Cable Assemblies, 6 kV, IP30, in plugged and mounted condition, 300 V, Li9YH 1 x 0,75, 1.2 m
GTIN (EAN)	4099986795716	
Qty.	10 ST	
Type	CH-SMR-00.33-VCC180 VPE...	Version
Order No.	2924970033	Smart Metering Cable Assemblies, 6 kV, IP30, in plugged and mounted condition, 300 V, Li9YH 1 x 0,75,
GTIN (EAN)	4099986795624	
Qty.	10 ST	
Type	CH-SMR-00.33-YCC90 VPE10	Version
Order No.	2924960033	Smart Metering Cable Assemblies, 6 kV, IP30, in plugged and mounted condition, 300 V, Li9YH 1 x 0,75,
GTIN (EAN)	4099986795617	
Qty.	10 ST	
Type	CH-SMR-00.60-OVP180 VPE...	Version
Order No.	2924810060	Smart Metering Cable Assemblies, 6 kV, IP30, in plugged and mounted condition, 300 V, Li9YH 1 x 0,75, 0.6 m
GTIN (EAN)	4099986993440	
Qty.	10 ST	
Type	CH-SMR-00.80-OVP180 VPE...	Version
Order No.	2924810080	Smart Metering Cable Assemblies, 6 kV, IP30, in plugged and mounted condition, 300 V, Li9YH 1 x 0,75, 0.8 m
GTIN (EAN)	4099986993457	
Qty.	10 ST	
Type	CH-SMR-01.15-OVP180 VPE...	Version
Order No.	2924810115	Smart Metering Cable Assemblies, 6 kV, IP30, in plugged and mounted condition, 300 V, Li9YH 1 x 0,75, 1.15 m
GTIN (EAN)	4099986993464	
Qty.	10 ST	
Type	CH-SMR-00.60-OVP90 VPE10	Version
Order No.	2924820060	Smart Metering Cable Assemblies, 6 kV, IP30, in plugged and mounted condition, 300 V, Li9YH 1 x 0,75, 0.6 m
GTIN (EAN)	4099986993471	
Qty.	10 ST	
Type	CH-SMR-00.80-OVP90 VPE10	Version
Order No.	2924820080	Smart Metering Cable Assemblies, 6 kV, IP30, in plugged and mounted condition, 300 V, Li9YH 1 x 0,75, 0.8 m
GTIN (EAN)	4099986993488	
Qty.	10 ST	
Type	CH-SMR-01.15-OVP90 VPE10	Version
Order No.	2924820115	Smart Metering Cable Assemblies, 6 kV, IP30, in plugged and mounted condition, 300 V, Li9YH 1 x 0,75, 1.15 m
GTIN (EAN)	4099986993495	
Qty.	10 ST	