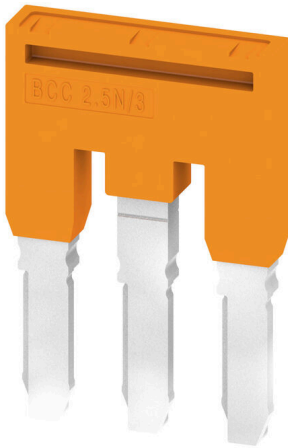


**BCC 2.5N/3****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**General ordering data**

Version	Cross-connector (terminal), Plugged, orange, 24 A, Number of poles: 3, Pitch in mm (P): 5.10, Insulated: Yes, Width: 13.7 mm
Order No.	<a href="#">3040590000</a>
Type	BCC 2.5N/3
GTIN (EAN)	4099987010252
Qty.	50 items

**BCC 2.5N/3**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Dimensions and weights**

Depth	20.5 mm	Depth (inches)	0.8071 inch
Height	2.6 mm	Height (inches)	0.1024 inch
Width	13.7 mm	Width (inches)	0.5394 inch
Net weight	2 g		

**Temperatures**

Storage temperature	-25 °C...55 °C	Ambient temperature	-5 °C...40 °C
Continuous operating temp., min.	-50 °C	Continuous operating temp., max.	120 °C

**Environmental Product Compliance**

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

**Material data**

Basic material	PA 66	Colour	orange
UL 94 flammability rating	V-0		

**Additional technical data**

Type of fixing	Plugged	Type of mounting	Direct mounting
----------------	---------	------------------	-----------------

**Dimensions**

Pitch in mm (P)	5.10 mm
-----------------	---------

**General**

Number of poles	3
-----------------	---

**Rating data**

Rated voltage	400 V	Nominal current	24 A
---------------	-------	-----------------	------

**Classifications**

ETIM 8.0	EC000489	ETIM 9.0	EC000489
ETIM 10.0	EC000489	ECLASS 14.0	27-25-03-03
ECLASS 15.0	27-25-03-03		