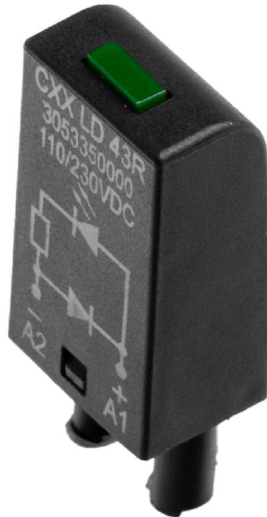


**CXX LD 43G****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**General ordering data**

|            |                                                                                                           |
|------------|-----------------------------------------------------------------------------------------------------------|
| Version    | CUBESERIES, LED module with freewheel diode,<br>Rated control voltage: 110...230 V DC, Plug-in connection |
| Order No.  | <a href="#">3053360000</a>                                                                                |
| Type       | CXX LD 43G                                                                                                |
| GTIN (EAN) | 4099987023153                                                                                             |
| Qty.       | 20 items                                                                                                  |

## Technical data

### Approvals

|      |         |
|------|---------|
| ROHS | Conform |
|------|---------|

### Dimensions and weights

|            |         |                 |             |
|------------|---------|-----------------|-------------|
| Depth      | 25.7 mm | Depth (inches)  | 1.0118 inch |
| Height     | 9.2 mm  | Height (inches) | 0.3622 inch |
| Width      | 12.8 mm | Width (inches)  | 0.5039 inch |
| Net weight | 2 g     |                 |             |

### Temperatures

|                       |                |                     |                |
|-----------------------|----------------|---------------------|----------------|
| Storage temperature   | -40 °C...85 °C | Ambient temperature | -40 °C...70 °C |
| Operating temperature |                |                     |                |

### Environmental Product Compliance

|                        |                             |
|------------------------|-----------------------------|
| RoHS Compliance Status | Compliant without exemption |
| REACH SVHC             | No SVHC above 0.1 wt%       |

### Control side

|                       |                |                    |                     |
|-----------------------|----------------|--------------------|---------------------|
| Rated control voltage | 110...230 V DC | Rated current DC   | 4 mA                |
| Status indicator      | Green LED      | Protective circuit | Free-wheeling diode |

### General data

|                                    |                          |         |  |
|------------------------------------|--------------------------|---------|--|
| Colour                             | black                    |         |  |
| UL94 flammability rating component | Component                | Housing |  |
|                                    | UL94 flammability rating | V-2     |  |

### Connection data


|                        |                    |
|------------------------|--------------------|
| Wire connection method | Plug-in connection |
|------------------------|--------------------|

### Classifications


|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 6.0    | EC002586    | ETIM 7.0    | EC002586    |
| ETIM 8.0    | EC002586    | ETIM 9.0    | EC002586    |
| ETIM 10.0   | EC002586    | ECLASS 9.1  | 27-37-10-10 |
| ECLASS 10.0 | 27-37-10-10 | ECLASS 11.0 | 27-37-16-92 |
| ECLASS 12.0 | 27-37-16-92 | ECLASS 13.0 | 27-37-16-92 |
| ECLASS 14.0 | 27-37-16-92 | ECLASS 15.0 | 27-37-16-92 |

## Drawings

### Connection diagram

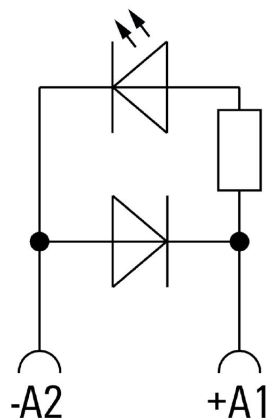

### Dimensional drawing

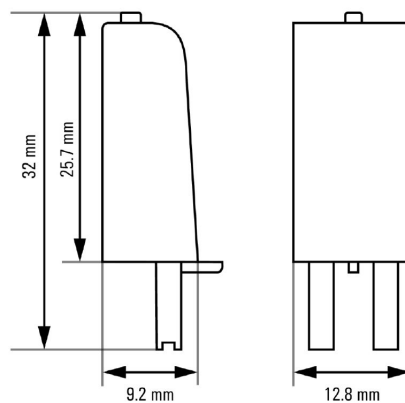

## Miscellaneous

## Type code CUBESERIES LED / protective module versions

