

CXX RC 53

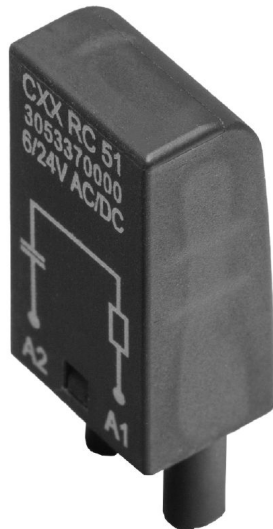
Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com



Similar to illustration

General ordering data

Version	CUBESERIES, RC element, Rated control voltage: 110...230 V AC, Plug-in connection
Order No.	3053400000
Type	CXX RC 53
GTIN (EAN)	4099987023184
Qty.	20 items

CXX RC 53**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com
Technical data**Approvals**

ROHS	Conform
------	---------

Dimensions and weights

Depth	23 mm	Depth (inches)	0.9055 inch
Height	9.2 mm	Height (inches)	0.3622 inch
Width	12.8 mm	Width (inches)	0.5039 inch
Net weight	2 g		

Temperatures

Storage temperature	-40 °C...85 °C	Ambient temperature	-40 °C...70 °C
Operating temperature			

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Control side

Rated control voltage	110...230 V AC	Status indicator	No
Protective circuit	RC element		

General data

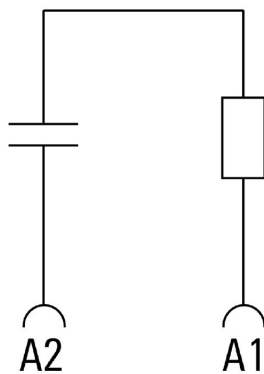
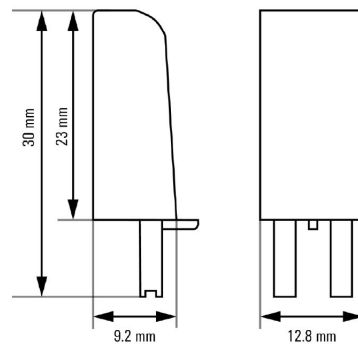
Colour	black	
UL94 flammability rating component	Component	Housing
	UL94 flammability rating	V-2

Connection data

Wire connection method	Plug-in connection
------------------------	--------------------

Classifications

ETIM 8.0	EC002586	ETIM 9.0	EC002586
ETIM 10.0	EC002586	ECLASS 14.0	27-37-16-92
ECLASS 15.0	27-37-16-92		

Drawings**Connection diagram****Dimensional drawing**

Miscellaneous

Type code CUBESERIES LED / protective module versions

