


## CXX RC 53

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

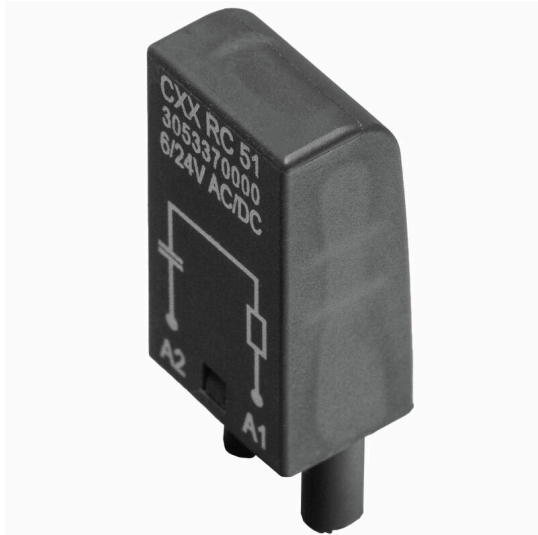

Similar to illustration

### General ordering data

Version	CUBESERIES, RC element, Rated control voltage: 110...230 V AC, Plug-in connection
Order No.	<a href="#">3053400000</a>
Type	CXX RC 53
GTIN (EAN)	4099987023184
Qty.	20 items

## CXX RC 53

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Approvals

ROHS	Conform
------	---------

## Dimensions and weights

Depth	23 mm	Depth (inches)	0.9055 inch
Height	9.2 mm	Height (inches)	0.3622 inch
Width	12.8 mm	Width (inches)	0.5039 inch
Net weight	2 g		

## Temperatures

Storage temperature	-40 °C...85 °C	Ambient temperature	-40 °C...70 °C
Operating temperature			

## Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

## Control side

Rated control voltage	110...230 V AC	Status indicator	No
Protective circuit	RC element		

## General data

Colour	black		
UL94 flammability rating component	Component	Housing	
	UL94 flammability rating	V-2	

## Connection data

Wire connection method	Plug-in connection
------------------------	--------------------

## Classifications

ETIM 8.0	EC002586	ETIM 9.0	EC002586
ETIM 10.0	EC002586	ECLASS 14.0	27-37-16-92
ECLASS 15.0	27-37-16-92		

Drawings

Connection diagram



Dimensional drawing



Miscellaneous

Type code CUBESERIES LED / protective module versions

