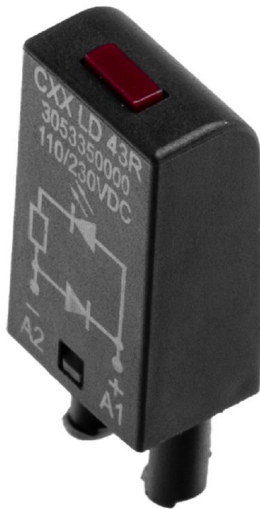


CXX L 63R**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Similar to illustration

General ordering data

Version	CUBESERIES, LED module, Rated control voltage: 110...230 V UC, Plug-in connection
Order No.	3053450000
Type	CXX L 63R
GTIN (EAN)	4099987023238
Qty.	20 items

CXX L 63R**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data**Approvals**

ROHS	Conform
------	---------

Dimensions and weights

Depth	25.7 mm	Depth (inches)	1.0118 inch
Height	9.2 mm	Height (inches)	0.3622 inch
Width	12.8 mm	Width (inches)	0.5039 inch
Net weight	2 g		

Temperatures

Storage temperature	-40 °C...85 °C	Ambient temperature	-40 °C...70 °C
Operating temperature			

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Control side

Rated control voltage	110...230 V UC	Rated current AC	4.3 mA
Rated current DC	4.3 mA	Status indicator	Red LED

General data

Colour	black		
UL94 flammability rating component	Component	Housing	
	UL94 flammability rating	V-2	

Connection data


Wire connection method	Plug-in connection
------------------------	--------------------

Classifications


ETIM 6.0	EC002586	ETIM 7.0	EC002586
ETIM 8.0	EC002586	ETIM 9.0	EC002586
ETIM 10.0	EC002586	ECLASS 9.1	27-37-10-10
ECLASS 10.0	27-37-10-10	ECLASS 11.0	27-37-16-92
ECLASS 12.0	27-37-16-92	ECLASS 13.0	27-37-16-92
ECLASS 14.0	27-37-16-92	ECLASS 15.0	27-37-16-92

Drawings

Connection diagram

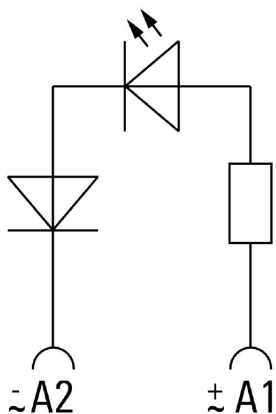

Dimensional drawing

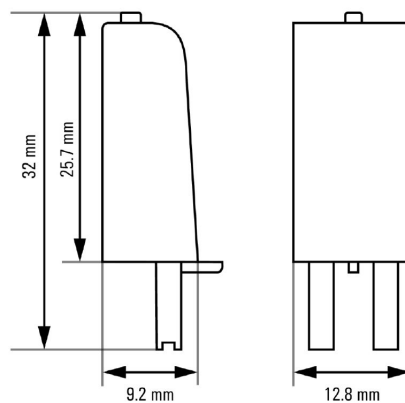

Miscellaneous

Type code CUBESERIES LED / protective module versions

