

CXX V 72


Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

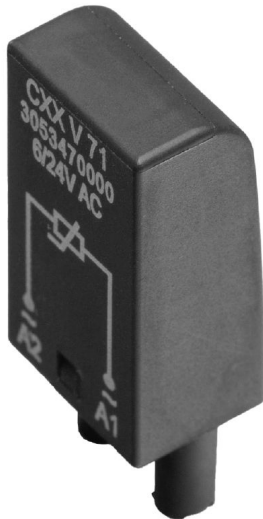

Similar to illustration

General ordering data

Version	CUBESERIES, Protective varistor, Rated control voltage: 110...130 V AC, Plug-in connection
Order No.	3053480000
Type	CXX V 72
GTIN (EAN)	4099987023269
Qty.	20 items

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Depth	23 mm	Depth (inches)	0.9055 inch
Height	9.2 mm	Height (inches)	0.3622 inch
Width	12.8 mm	Width (inches)	0.5039 inch
Net weight	2 g		

Temperatures

Storage temperature	-40 °C...85 °C	Ambient temperature	-40 °C...70 °C
Operating temperature			

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Control side

Rated control voltage	110...130 V AC	Status indicator	No
Protective circuit	Varistor		

General data

Colour	black	
UL94 flammability rating component	Component	Housing
	UL94 flammability rating	V-2

Connection data


Wire connection method	Plug-in connection
------------------------	--------------------

Classifications


ETIM 6.0	EC002586	ETIM 7.0	EC002586
ETIM 8.0	EC002586	ETIM 9.0	EC002586
ETIM 10.0	EC002586	ECLASS 9.1	27-37-10-10
ECLASS 10.0	27-37-10-10	ECLASS 11.0	27-37-16-92
ECLASS 12.0	27-37-16-92	ECLASS 13.0	27-37-16-92
ECLASS 14.0	27-37-16-92	ECLASS 15.0	27-37-16-92

Drawings

Connection diagram

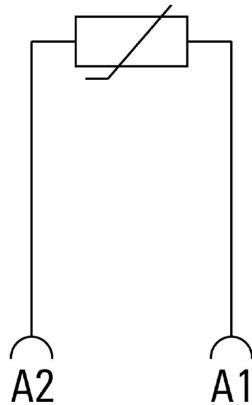

Dimensional drawing

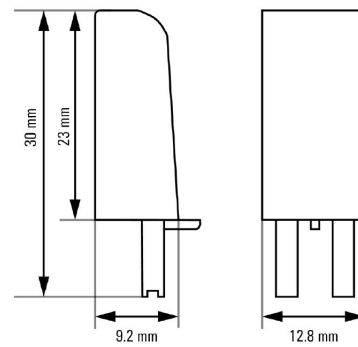

Miscellaneous

Type code CUBESERIES LED / protective module versions

