


THM WO-R VIN 25.4/57.2 WS

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

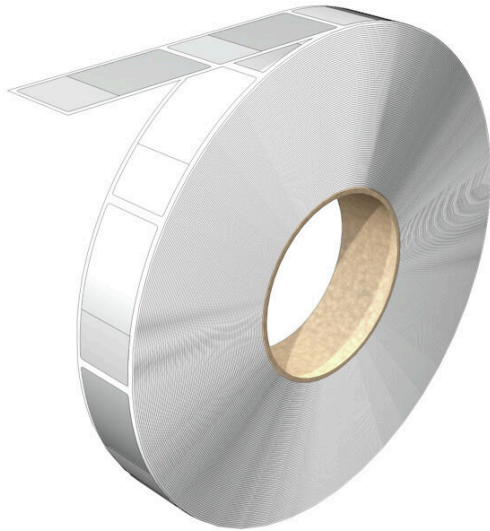

General ordering data

Order No.	3062890000
Type	THM WO-R VIN 25.4/57.2 WS
GTIN (EAN)	4099987049283
Qty.	2750 items

THM WO-R VIN 25.4/57.2 WS

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Depth	0.07 mm	Depth (inches)	0.0028 inch
Height	25.4 mm	Height (inches)	1 inch
Width	57.2 mm	Width (inches)	2.252 inch
Net weight	0.32 g		

General data

Type of printing	neutral	Width	57.2 mm
UL 94 flammability rating	V-0	Operating temperature range, max.	80 °C
Operating temperature range, min.	-40 °C	Colour	white
Halogen	Yes	Basic material	Vinyl film
Printed characters	without	Size of labelling field	19.1 x 25.4 mm
Number per roll	2750		

Conductor and cable markers

Halogen	Yes
---------	-----

Classifications

ETIM 8.0	EC001530	ETIM 9.0	EC001530
ETIM 10.0	EC001530	ECLASS 14.0	27-28-11-02
ECLASS 15.0	27-28-11-02		