


BEP 2T 2.5N BL

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

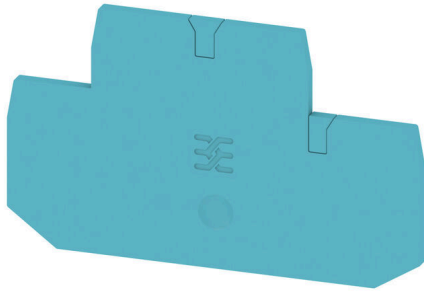

General ordering data

Version	B-series, End plate
Order No.	3076080000
Type	BEP 2T 2.5N BL
GTIN (EAN)	4099987079952
Qty.	20 items

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Depth	42.5 mm	Depth (inches)	1.6732 inch
Height	72 mm	Height (inches)	2.8346 inch
Width	2.1 mm	Width (inches)	0.0827 inch
Net weight	2.99 g		

Temperatures

Storage temperature	-25 °C...55 °C	Ambient temperature	-5 °C...40 °C
Continuous operating temp., min.	-50 °C	Continuous operating temp., max.	120 °C

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Material data

Basic material	PA 66	Colour	blue
UL 94 flammability rating	V-0		

System specifications

Version	End plate
---------	-----------

Additional technical data

With snap-in pegs	Yes	Snap-on	Yes
-------------------	-----	---------	-----

Classifications

ETIM 8.0	EC000886	ETIM 9.0	EC000886
ETIM 10.0	EC000886	ECLASS 14.0	27-25-03-01
ECLASS 15.0	27-25-03-01		