

WIL-VRGBW-FPPF-XXXX-X265-X

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com



General ordering data

Order No.	3101700000
Type	WIL-VRGBW-FPPF-XXXX-X265-X
GTIN (EAN)	4099987143158
Qty.	1 items

WIL-VRGBW-FPPF-XXXX-X265-X

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Depth	10 mm	Depth (inches)	0.3937 inch
Height	10 mm	Height (inches)	0.3937 inch
Length	265 mm	Length (inches)	10.433 inch
Net weight	205 g		

Temperatures

Operating temperature	-20 - 50°C
-----------------------	------------

Environmental Product Compliance

RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	6c
REACH SVHC	Lead 7439-92-1
SCIP	37ebc061-1fa2-4387-80af-82299a5c3412

Cable technical specifications

Cable Material	PUR	Sheathing colour	black
Housing main material	Aluminium	Cable length	5 m

Connection data

Connection thread	without
-------------------	---------

Electric data

Rated voltage	≤ 5 V DC	Power	1.2 W
Dimmable	Yes		

General technical data

Shape of the LED module	Rectangular	Operating life	60.000 h
Protection degree	IP67	Efficiency class (according to EU Directive No. 874/2012)	Not required

Material data


Housing main material	Aluminium	Encapsulation compound	PUR V0
-----------------------	-----------	------------------------	--------

Classifications

ETIM 8.0	EC000996	ETIM 9.0	EC000996
ETIM 10.0	EC000996	ECLASS 14.0	27-11-06-35
ECLASS 15.0	27-11-06-35		

Drawings

Drawing

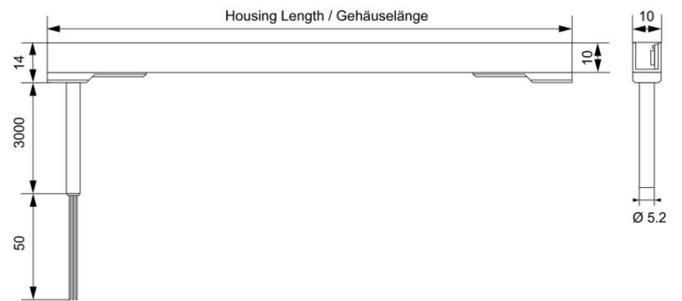

WIL-VRGBW-FPPF-XXXX-X265-X

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Accessories

M8 / M12 mounting clip



Weidmüller offers a wide range of tools and accessories for sensor-actuator cabling.

General ordering data

Type	SAI-M12-CLIP	Version	
Order No.	1362750000		
GTIN (EAN)	4050118164879		
Qty.	10 ST		