

HDC 16B SS 1M32G ATEX**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

The option of separating cables in Zone 2 that comply with the following approvals ATEX: T II 3G Ex ec IIC T6 Gc or IECEX: Ex ec IIC T6 Gc simplifies installation, service and enables better preparation. The approved connectors offered here must always be used complete with the corresponding approved housings and inserts and may only be disconnected without load.

General ordering data

Version	HDC enclosures, Installation size: 6, Protection degree: IP55, Base housing, Clamping yoke connection, Standard, Size of cable entries: M 32
Order No.	3139870000
Type	HDC 16B SS 1M32G ATEX
GTIN (EAN)	4099987382236
Qty.	1 items

HDC 16B SS 1M32G ATEX

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

Approvals



Dimensions and weights

Depth	189 mm	Depth (inches)	7.4409 inch
Height	111.5 mm	Height (inches)	4.3898 inch
Width	80 mm	Width (inches)	3.1496 inch
Mounting dimension - height	60 mm	Mounting dimension - width	160 mm
Net weight	1039 g		

Temperatures

Ambient temperature	-20 °C...40 °C	Limit temperature	-20 °C ... 80 °C
---------------------	----------------	-------------------	------------------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Dimensions

Width	80 mm
-------	-------

General data

Design of housing	Base housing	Installation size	6
UL 94 flammability rating	V-0	Colour	grey
Housing main material	diecast aluminium	Surface finish	Miscellaneous
Type	Base housing	Free from halogens	false
EMC housings	Yes	BG	6
Protection degree	IP55		

Rating data IECEx/ATEX

Certificate No. (IECEX)	TUEV24ATEX9197X	Certificate No. (ATEX)	IECEXUR24.0077X
-------------------------	-----------------	------------------------	-----------------

Version

Installation size	6	Surface finish	Miscellaneous
BG	6		

Classifications


ETIM 8.0	EC000437	ETIM 9.0	EC000437
ETIM 10.0	EC000437	ECLASS 14.0	27-44-02-02
ECLASS 15.0	27-44-02-02		

HDC 16B SS 1M32G ATEX

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

Drawings

www.weidmueller.com

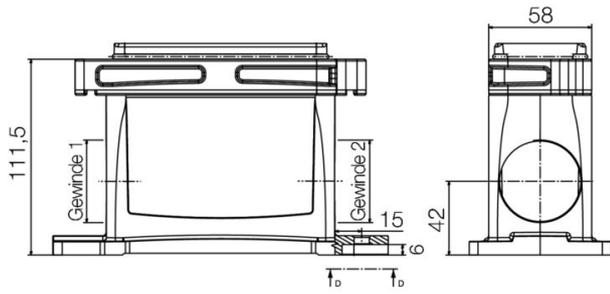

HDC 16B SS 1M32G ATEX

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Size 6 (16B)



The option of separating cables in Zone 2 that comply with the following approvals ATEX: T II 3G Ex ec IIC T6 Gc or IECEX: Ex ec IIC T6 Gc simplifies installation, service and enables better preparation. The approved connectors offered here must always be used complete with the corresponding approved housings and inserts and may only be disconnected without load.

General ordering data

Type	HDC 16B TOS 1M32G ATEX	Version
Order No.	3139980000	HDC enclosures, Installation size: 6, Protection degree: IP55, Plug
GTIN (EAN)	4099987382342	housing, Clamping yoke connection, Standard, Size of cable entries:
Qty.	1 ST	M 32
Type	HDC 16B TOS 2M25G ATEX	Version
Order No.	3139990000	HDC enclosures, Installation size: 6, Protection degree: IP55, Plug
GTIN (EAN)	4099987382359	housing, Clamping yoke connection, Standard, Size of cable entries:
Qty.	1 ST	M 32, M 25
Type	HDC 16B TSS 1M32G ATEX	Version
Order No.	3140000000	HDC enclosures, Installation size: 6, Protection degree: IP55, Plug
GTIN (EAN)	4099987382366	housing, Clamping yoke connection, Standard, Size of cable entries:
Qty.	1 ST	M 32
Type	HDC 16B COVER ATEX	Version
Order No.	3140070000	HDC enclosures, Installation size: 6, Protection degree: IP55, Cover for
GTIN (EAN)	4099987382434	lower part of housing, Clamping yoke connection, Standard, Size of
Qty.	1 ST	cable entries: none

Size 6



**IECEX
ATEX**

The option of separating cables in Zone 2 that comply with the following approvals ATEX: T II 3G Ex ec IIC T6 Gc or IECEX: Ex ec IIC T6 Gc simplifies installation, service and enables better preparation. The approved connectors offered here must always be used complete with the corresponding approved housings and inserts and may only be disconnected without load.

General ordering data

Type	HDC HDD 24 FC EX 1500	Version
Order No.	3116650000	HDC insert, Female, 1500 V, Number of poles: 24, Crimp connection,
GTIN (EAN)	4099987235778	Installation size: 6
Qty.	1 ST	
Type	HDC HDD 24 MC EX 1500	Version
Order No.	3116630000	HDC insert, Male, 1500 V, Number of poles: 24, Crimp connection,
GTIN (EAN)	4099987235754	Installation size: 6
Qty.	1 ST	

HDC 16B SS 1M32G ATEX

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Accessories

Type	HDC HDD 32 FC EX 1000	Version
Order No.	3116640000	HDC insert, Female, 1000 V, Number of poles: 32, Crimp connection,
GTIN (EAN)	4099987235761	Installation size: 6
Qty.	1 ST	
Type	HDC HDD 32 MC EX 1000	Version
Order No.	3116620000	HDC insert, Male, 1000 V, Number of poles: 32, Crimp connection,
GTIN (EAN)	4099987235747	Installation size: 6
Qty.	1 ST	