

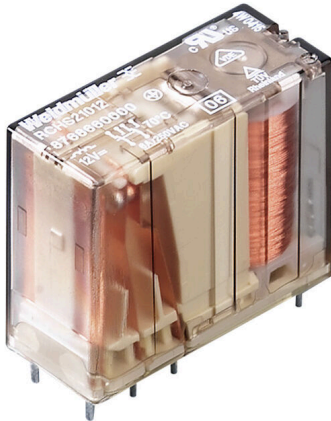
RCH310024**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Product image

Similar to illustration

General ordering data

Version	RIDERSERIES, Relay, Number of contacts: 1, CO contact AgNi, Plug-in connection
Order No.	4064580000
Type	RCH310024
GTIN (EAN)	4032248412655
Qty.	20 items
Delivery status	This article will no longer be available in the future.
Available until	2025-06-30T00:00:00+02:00

RCH310024

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate No. (cURus)	E522350

Dimensions and weights

Depth	25.5 mm	Depth (inches)	1.0039 inch
Height	29 mm	Height (inches)	1.1417 inch
Width	12.6 mm	Width (inches)	0.4961 inch
Net weight	18 g		

Temperatures

Storage temperature	Ambient temperature	-40 °C...70 °C
Operating temperature		

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Rated data UL

Certificate No. (cURus)	E522350
-------------------------	---------

Control side

Status indicator	No
------------------	----

Load side

Contact type	1 CO contact (AgNi)
--------------	---------------------

General data

Colour	Transparent
--------	-------------

Insulation coordination

Protection degree	IP40
-------------------	------

Further details of approvals / standards

Certificate No. (VDE)	40015457	Certificate No. (cURus)	E522350
-----------------------	----------	-------------------------	---------

Connection data

Wire connection method	Plug-in connection
------------------------	--------------------

Technical data

Classifications

ETIM 8.0	EC001437	ETIM 9.0	EC001437
ETIM 10.0	EC001437	ECLASS 14.0	27-37-16-01
ECLASS 15.0	27-37-16-01		