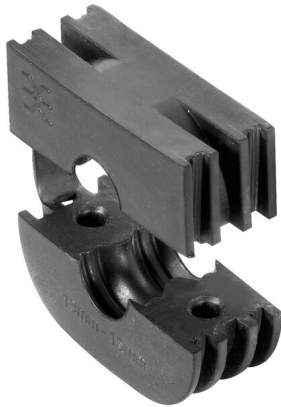


RKDG D15 PT6**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Intelligent cabling solutions can save you valuable time and money.

The FieldPower® modular system contains the right solution for every cabling task.

Foldable seals for the use of pre-assembled cables

Seals available with M16 and M20 connection thread

Integration of operating and signalling devices into the seal possible

General ordering data

Version	Field Power® sealing insert, Foldable seal, IP65 with corresponding housing, IP65, with corresponding enclosure, EPDM
Order No.	4323220000
Type	RKDG D15 PT6
GTIN (EAN)	4032248641222
Qty.	10 items

RKDG D15 PT6

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Depth	18 mm	Depth (inches)	0.7087 inch
Height	33.8 mm	Height (inches)	1.3307 inch
Width	46.7 mm	Width (inches)	1.8386 inch
Net weight	23 g		

Temperatures

Storage temperature	-40 °C...85 °C	Operating temperature	-40 °C...85 °C
---------------------	----------------	-----------------------	----------------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

General data

Basic material	EPDM	Silicone	No
Colour	black	Design	Foldable seal
Protection degree	IP65 with corresponding housing, IP65, with corresponding enclosure	UL 94 flammability rating	HB
Mounting position, installation notice	in FieldPower® sealing slot	Line type	round
Outer cable diameter, min.	13 mm	Outer cable diameter, max.	15 mm

Classifications

ETIM 8.0	EC002624	ETIM 9.0	EC002624
ETIM 10.0	EC002624	ECLASS 14.0	27-18-28-15
ECLASS 15.0	27-18-28-15		