


MODICON QUANTUM MIG MOD,40 POL

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

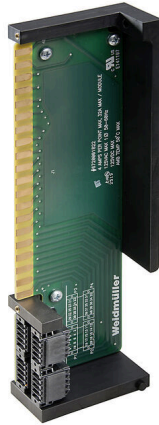

General ordering data

Order No.	6720001822
Type	MODICON QUANTUM MIG MOD,40 POL
GTIN (EAN)	405011872982
Qty.	1 items

MODICON QUANTUM MIG MOD,40 POL

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS Conform

Dimensions and weights

Depth	76 mm	Depth (inches)	2.9921 inch
Height	250 mm	Height (inches)	9.8425 inch
Width	41 mm	Width (inches)	1.6142 inch
Net weight	336.16 g		

Temperatures

Storage temperature	0...50 °C	Operating temperature	0...50 °C
Operating temperature range	-20...50 °C		

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Rated data UL

Operating temperature UL, min.	0 °C	Operating temperature UL, max.	50 °C
Rated current I _{max}	4 A	Rated voltage UN	125V AC / 125V DC max.

Classifications

ETIM 8.0	EC002584	ETIM 9.0	EC002584
ETIM 10.0	EC002584	ECLASS 14.0	27-33-02-92
ECLASS 15.0	27-33-02-92		