

DRI314615L

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Product image



Similar to illustration

Individual relays within the D-SERIES DRI

- 1 CO contact
- AC coils
- With integrated status LED

General ordering data

| | |
|------------|----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Version | D-SERIES DRI, Relay, Number of contacts: 1, CO contact AgSnO, Rated control voltage: 115 V AC, Continuous current: 10 A, Flat blade connections (4.7 mm x 0.5 mm), Test button available: No |
| Order No. | 7760056308 |
| Type | DRI314615L |
| GTIN (EAN) | 6944169740138 |
| Qty. | 20 items |

DRI314615L

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS Conform

UL File Number Search [UL Website](#)

Certificate No. (cURus) E312083

Dimensions and weights

| | | | |
|------------|-------|-----------------|-------------|
| Depth | 28 mm | Depth (inches) | 1.1024 inch |
| Height | 31 mm | Height (inches) | 1.2205 inch |
| Width | 13 mm | Width (inches) | 0.5118 inch |
| Net weight | 19 g | | |

Temperatures

| | | | |
|-----------------------|----------------|---------------------|------------------------------------------|
| Storage temperature | -40 °C...85 °C | Ambient temperature | -40 °C...55 °C |
| Operating temperature | | Humidity | 35...85 % rel. humidity, no condensation |

Environmental Product Compliance

| | |
|------------------------|-----------------------------|
| RoHS Compliance Status | Compliant without exemption |
| REACH SVHC | No SVHC above 0.1 wt% |

Rated data UL

Certificate No. (cURus) E312083

Control side

| | | | |
|-----------------------|----------|------------------|---------------|
| Rated control voltage | 115 V AC | Rated current AC | 9.3 mA |
| Power rating | 1.1 VA | Coil resistance | 6200 Ω ± 10 % |
| Status indicator | red LED | | |

Load side

| | | | |
|-----------------------------------------|---------------------------------------|-----------------------------------------|------------------------------------------|
| Rated switching voltage | 250 V AC | Continuous current | 10 A |
| Max. switching frequency at rated load | 0.1 Hz | Max. switching voltage, AC | 250 V |
| Max. switching voltage, DC | 250 V | AC switching capacity (resistive), max. | 2500 VA |
| DC switching capacity (resistive), max. | 240 W @ 24 V | Switch-on delay | ≤ 15 ms |
| Switch-off delay | ≤ 10 ms | Contact type | 1 CO contact (AgSnO) |
| Mechanical service life | 10 x 10 ⁶ switching cycles | Min. switching power | 10 mA @ 24 V, 10 mA @ 12 V, 100 mA @ 5 V |

General data

| | | | |
|--------------------------------------|--------------------------|-----------------|--|
| Test button available | No | | |
| Mechanical switch position indicator | No | | |
| Colour | Transparent | | |
| UL94 flammability rating component | Component | Relay cover | |
| | UL94 flammability rating | V-2 | |
| | Component | Relay baseplate | |
| | UL94 flammability rating | V-0 | |

DRI314615L

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Insulation coordination

| | | | |
|---------------------------------------------------------------|-----------------|--------------------------------------------------|------------------|
| Rated voltage | 300 V | Pollution severity | 2 |
| Surge voltage category | III | Insulating material group | IIIa |
| Clearance and creepage distances for control side - load side | ≥ 4 mm | Dielectric strength for control side - load side | 5 kVeff / 1min |
| Dielectric strength of open contact | 1 kVeff / 1 min | Impulse withstand voltage | 5 kV (1.2/50 µs) |
| Protection degree | IP20 | | |

Further details of approvals / standards

| | |
|-------------------------|---------|
| Certificate No. (cURus) | E312083 |
|-------------------------|---------|


Connection data

| | |
|------------------------|------------------------------------------|
| Wire connection method | Flat blade connections (4.7 mm x 0.5 mm) |
|------------------------|------------------------------------------|

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 8.0 | EC001437 | ETIM 9.0 | EC001437 |
| ETIM 10.0 | EC001437 | ECLASS 14.0 | 27-37-16-01 |
| ECLASS 15.0 | 27-37-16-01 | | |

Wiring diagram

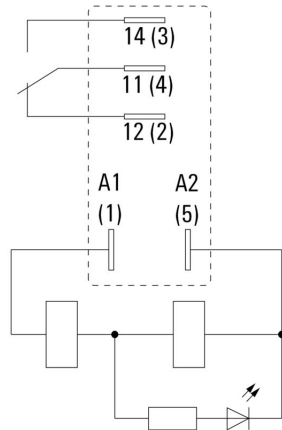

View of Pins from below

Graph



DC load limit curve Resistive load

Graph



Electrical service life

Graph



AC operational voltage range

Dimensional drawing




DRI314615L

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

Drawings

www.weidmueller.com

Miscellaneous

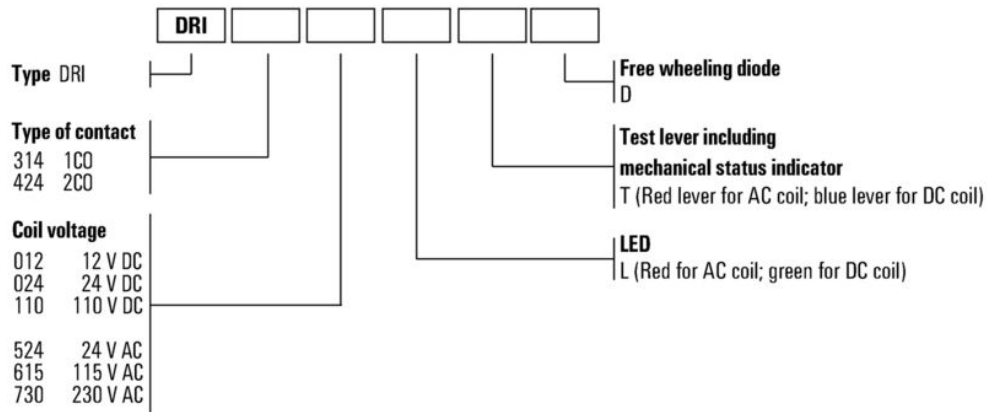

Type codes

DRI314615L

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

Accessories

www.weidmueller.com

Sockets



Relay sockets for the D-SERIES DRI relays

- 1 and 2 CO contacts
- Screw and PUSH IN connection
- Standard and low heights

General ordering data

| | | |
|------------|----------------------------|----------------------------------------------------------------|
| Type | SDI 1CO | Version |
| Order No. | 7760056350 | D-SERIES DRI, Relay socket, Number of contacts: 1, CO contact, |
| GTIN (EAN) | 6944 169739972 | Continuous current: 12 A, Screw connection |
| Qty. | 10 ST | |
| Type | SDI 1CO ECO | Version |
| Order No. | 7760056346 | D-SERIES DRI, Relay socket, Number of contacts: 1, CO contact, |
| GTIN (EAN) | 6944 169739934 | Continuous current: 12 A, Screw connection |
| Qty. | 10 ST | |
| Type | SDI 1CO F ECO | Version |
| Order No. | 7760056348 | D-SERIES DRI, Relay socket, Number of contacts: 1, CO contact, |
| GTIN (EAN) | 6944 169739958 | Continuous current: 12 A, Screw connection |
| Qty. | 10 ST | |
| Type | SDI 1CO P | Version |
| Order No. | 7760056364 | D-SERIES DRI, Relay socket, Number of contacts: 1, CO contact, |
| GTIN (EAN) | 6944 169772283 | Continuous current: 12 A, PUSH IN |
| Qty. | 20 ST | |

LED



Pluggable protective modules for the D-SERIES relay sockets, with optional protective functions.

- With green LED

General ordering data

| | | |
|------------|----------------------------|--------------------------------------------------------------------|
| Type | RIM 3 110/230VUC | Version |
| Order No. | 7940018455 | D-SERIES, LED module, Rated control voltage: 110...230 V UC, Plug- |
| GTIN (EAN) | 4032248878185 | in connection |
| Qty. | 10 ST | |

DRI314615L

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Protection modules



Pluggable protective modules for the D-SERIES relay sockets, with optional protective functions.

- With free-wheeling diode or RC filter

General ordering data

| | | | |
|------------|----------------------------|--------------------------------------------------------------------------------|--|
| Type | RIM 3 110/230VAC | Version | |
| Order No. | 7760056014 | D-SERIES, RC filter, Rated control voltage: 110...230 V AC, Plug-in connection | |
| GTIN (EAN) | 4032248878109 | | |
| Qty. | 10 ST | | |
| Type | RIM 3 110/230VAC LED | Version | |
| Order No. | 7760056045 | D-SERIES, RC filter, Rated control voltage: 110...230 V AC, Plug-in connection | |
| GTIN (EAN) | 4032248878147 | | |
| Qty. | 10 ST | | |

Retaining clips



Retaining clip for D-SERIES DRI relays


- Metal and plastic retaining clip

General ordering data

| | | | |
|------------|----------------------------|------------------------------|--|
| Type | SDI CLIP | Version | |
| Order No. | 7760056352 | D-SERIES DRI, Retaining clip | |
| GTIN (EAN) | 6944169739996 | | |
| Qty. | 10 ST | | |
| Type | SDI CLIP P | Version | |
| Order No. | 7760056389 | D-SERIES DRI, Retaining clip | |
| GTIN (EAN) | 6944169787539 | | |
| Qty. | 10 ST | | |
| Type | SDI CLIP LM | Version | |
| Order No. | 7760056368 | D-SERIES DRI, Retaining clip | |
| GTIN (EAN) | 6944169773341 | | |
| Qty. | 10 ST | | |

Accessories

Blank

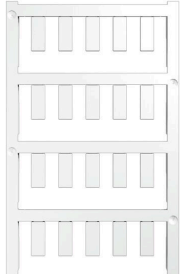

ESG is the tried-and-tested marker in MultiCard format for use on many well-known electrical devices. The result is high-quality device marking with a high-contrast appearance.

Various types are available for devices from manufacturers like Siemens, ABB, Beckhoff etc.

Advantages at a glance:


- Tags for universal usage, self-adhesive or clip-on tags, depending on type
- For aligned equipment, e.g. circuit breakers, we supply ESG markers for clipping onto tag rails
- Individual laser-quality printing according to specifications

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

| | | | |
|------------|----------------------------|--------------------------------------------------------------|--|
| Type | ESG 6/15 SDI MC NE WS | Version | |
| Order No. | 2558340000 | ESG, Device markers x 15 mm, PA 66, Colour: white, pluggable | |
| GTIN (EAN) | 4050118569056 | | |
| Qty. | 200 ST | | |

Custom printing

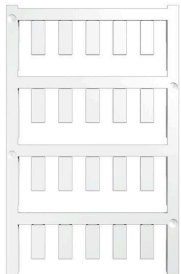

ESG is the tried-and-tested marker in MultiCard format for use on many well-known electrical devices. The result is high-quality device marking with a high-contrast appearance.

Various types are available for devices from manufacturers like Siemens, ABB, Beckhoff etc.

Advantages at a glance:

- Tags for universal usage, self-adhesive or clip-on tags, depending on type
- For aligned equipment, e.g. circuit breakers, we supply ESG markers for clipping onto tag rails
- Individual laser-quality printing according to specifications

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

| | | | |
|------------|----------------------------|----------------------------------------------------------------------------------|--|
| Type | ESG 6/15 SDI MC SDR | Version | |
| Order No. | 2558310000 | ESG, Device markers x 15 mm, PA 66, Colour: To customer specification, pluggable | |
| GTIN (EAN) | 4050118569025 | | |
| Qty. | 40 ST | | |

DRI314615L

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Accessories

ESG 6/15



Guaranteed long service life: ESG

The multi-colour and multi-format labels have a strong adhesive layer to ensure the best possible adhesion to the underlying surface. Double laminated polyester makes the basic material very thin and yet extremely tear-resistant.

Your benefits with MultiMark

- “Different materials for various requirements”
- Can be used with equipment from many manufacturers
- Device markers with a familiar design

General ordering data

| | | | |
|------------|----------------------------|---------------------------------------|--|
| Type | ESG 6/15 MM WS | Version | |
| Order No. | 2619940000 | ESG, Device markers, 6 x 15 mm, white | |
| GTIN (EAN) | 4050118626148 | | |
| Qty. | 3000 ST | | |

DRI314615L

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

Counterpart

www.weidmueller.com

Sockets



Relay sockets for the D-SERIES DRI relays

- 1 and 2 CO contacts
- Screw and PUSH IN connection
- Standard and low heights

General ordering data

| | | |
|------------|----------------------------|----------------------------------------------------------------|
| Type | SDI 1CO | Version |
| Order No. | 7760056350 | D-SERIES DRI, Relay socket, Number of contacts: 1, CO contact, |
| GTIN (EAN) | 6944169739972 | Continuous current: 12 A, Screw connection |
| Qty. | 10 ST | |
| Type | SDI 1CO ECO | Version |
| Order No. | 7760056346 | D-SERIES DRI, Relay socket, Number of contacts: 1, CO contact, |
| GTIN (EAN) | 6944169739934 | Continuous current: 12 A, Screw connection |
| Qty. | 10 ST | |
| Type | SDI 1CO F ECO | Version |
| Order No. | 7760056348 | D-SERIES DRI, Relay socket, Number of contacts: 1, CO contact, |
| GTIN (EAN) | 6944169739958 | Continuous current: 12 A, Screw connection |
| Qty. | 10 ST | |
| Type | SDI 1CO P | Version |
| Order No. | 7760056364 | D-SERIES DRI, Relay socket, Number of contacts: 1, CO contact, |
| GTIN (EAN) | 6944169772283 | Continuous current: 12 A, PUSH IN |
| Qty. | 20 ST | |