


**CB 370/3,5 NC****Weidmüller Interface GmbH & Co. KG**Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

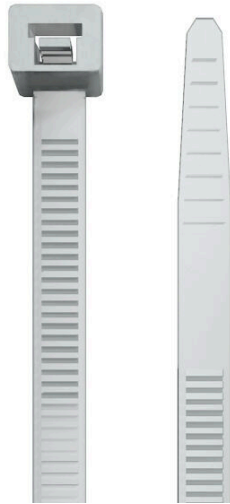

CB cable ties for the fastening of cables and markers.

- They are particularly suitable for fastening CLI M, SFX, WKM and WKS cable markers
- IEC 62275: 2006-conformant
- Fracture-resistant polyamide PA 6.6 with flammability rating V2 to UL-94

**General ordering data**

Version	Cable ties, 3.5 x 370 mm, Polyamide 66, 180 N
Order No.	<a href="#">7940006056</a>
Type	CB 370/3,5 NC
GTIN (EAN)	4032248527304
Qty.	4500 items

## Technical data

## Approvals

Approvals



ROHS Conform

UL File Number Search [UL Website](#)

Certificate No. (UR) E317499

## Dimensions and weights

Depth	1.4 mm	Depth (inches)	0.0551 inch
Height	370 mm	Height (inches)	14.5669 inch
Width	3.5 mm	Width (inches)	0.1378 inch
Net weight	1.93 g		

## Temperatures

Operating temperature range -40...85 °C

## Environmental Product Compliance

RoHS Compliance Status Compliant without exemption

REACH SVHC No SVHC above 0.1 wt%

## Installation materials

UV-resistant	No	For re-opening	No
UL 94 flammability rating	V-2	Operating temperature range, max.	85 °C
Operating temperature range, min.	-40 °C	Halogen	No
Cable diameter, max.	103 mm	Basic material	Polyamide 66
Tensile strength	180 N	Bundle diameter, max.	103 mm
Tensile strength (Pound-force)	40 lbf	Bundle diameter, min.	2 mm

## Important note

Product information  
Number of bags in box (pieces): 45  
Number of items in bag (pieces): 100  
One delivery unit corresponds to one box quantity, and only multiples of the delivery unit can be ordered.

## Classifications

ETIM 8.0	EC000046	ETIM 9.0	EC000046
ETIM 10.0	EC000046	ECLASS 14.0	27-14-07-02
ECLASS 15.0	27-14-07-02		

**Drawings**

