


CB 180/7,8 NC**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

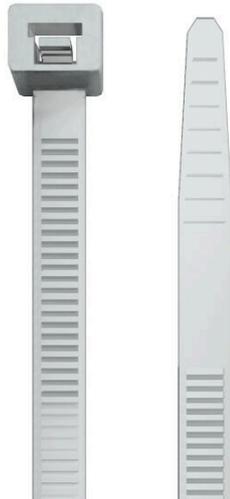

CB cable ties for the fastening of cables and markers.

- They are particularly suitable for fastening CLI M, SFX, WKM and WKS cable markers
- IEC 62275: 2006-conformant
- Fracture-resistant polyamide PA 6.6 with flammability rating V2 to UL-94

General ordering data

Version	Cable ties, 7.8 x 180 mm, Polyamide 66, 540 N
Order No.	7940006064
Type	CB 180/7,8 NC
GTIN (EAN)	4032248520169
Qty.	100 items

Technical data

Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate No. (UR)	E317499

Dimensions and weights

Depth	1.7 mm	Depth (inches)	0.0669 inch
Height	180 mm	Height (inches)	7.0866 inch
Width	7.8 mm	Width (inches)	0.3071 inch
Net weight	2.75 g		

Temperatures

Operating temperature range	-40...85 °C
-----------------------------	-------------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Installation materials

UV-resistant	No	For re-opening	No
UL 94 flammability rating	V-2	Operating temperature range, max.	85 °C
Operating temperature range, min.	-40 °C	Halogen	No
Cable diameter, max.	45 mm	Basic material	Polyamide 66
Tensile strength	540 N	Bundle diameter, max.	45 mm
Tensile strength (Pound-force)	121 lbf	Bundle diameter, min.	3.5 mm

Classifications

ETIM 8.0	EC000046	ETIM 9.0	EC000046
ETIM 10.0	EC000046	ECLASS 14.0	27-14-07-02
ECLASS 15.0	27-14-07-02		

Drawings

