

RIM 3 110/230VUC

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Product image

Similar to illustration

Pluggable protective modules for the D-SERIES relay sockets, with optional protective functions.

- With green LED

General ordering data

Version	D-SERIES, LED module, Rated control voltage: 110...230 V UC, Plug-in connection
Order No.	7940018455
Type	RIM 3 110/230VUC
GTIN (EAN)	4032248878185
Qty.	10 items

RIM 3 110/230VUC

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS Conform

UL File Number Search [UL Website](#)

Certificate No. (cURus) E312083

Dimensions and weights

Depth	32 mm	Depth (inches)	1.2598 inch
Height	8.6 mm	Height (inches)	0.3386 inch
Width	12.4 mm	Width (inches)	0.4882 inch
Net weight	1 g		

Temperatures

Storage temperature Operating temperature

Environmental Product Compliance

RoHS Compliance Status Compliant without exemption

REACH SVHC No SVHC above 0.1 wt%

Rated data UL

Certificate No. (cURus) E312083

Control side

Rated control voltage 110...230 V UC Status indicator Green LED

General data

Colour black

UL94 flammability rating component	Component	Housing
	UL94 flammability rating	V-2

Further details of approvals / standards

Certificate No. (CSA) 80107692 Certificate No. (cURus) E312083

Connection data

Wire connection method Plug-in connection

Classifications

ETIM 8.0	EC002586	ETIM 9.0	EC002586
ETIM 10.0	EC002586	ECLASS 14.0	27-37-16-92
ECLASS 15.0	27-37-16-92		


RIM 3 110/230VUC

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

Wiring diagram

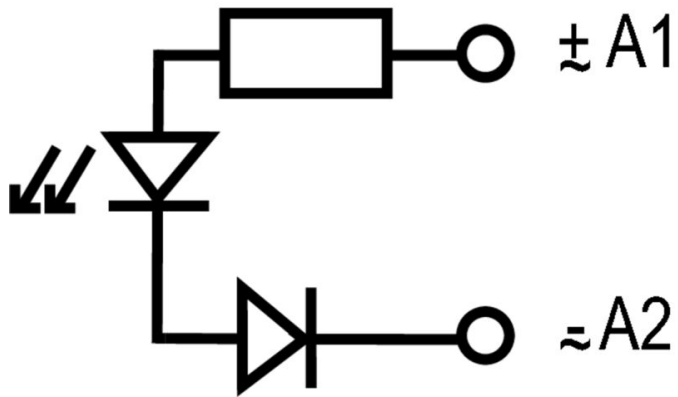

Dimensional drawing

