

RIM 3 6/24VUC

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Product image

Similar to illustration

Pluggable protective modules for the D-SERIES relay sockets, with optional protective functions.

- With green LED

General ordering data

Version	D-SERIES, LED module, Rated control voltage: 6... 24 V UC, Plug-in connection
Order No.	7940018457
Type	RIM 3 6/24VUC
GTIN (EAN)	4032248878192
Qty.	10 items

RIM 3 6/24VUC

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS Conform

UL File Number Search [UL Website](#)

Certificate No. (cURus) E312083

Dimensions and weights

Depth	32 mm	Depth (inches)	1.2598 inch
Height	8.6 mm	Height (inches)	0.3386 inch
Width	12.4 mm	Width (inches)	0.4882 inch
Net weight	0.95 g		

Temperatures

Storage temperature Operating temperature

Environmental Product Compliance

RoHS Compliance Status Compliant without exemption
REACH SVHC No SVHC above 0.1 wt%

Rated data UL

Certificate No. (cURus) E312083

Control side

Rated control voltage 6...24 V UC Status indicator Green LED

General data

Colour black
UL94 flammability rating component Component Housing
UL94 flammability rating V-2

Further details of approvals / standards

Certificate No. (CSA) 80107692 Certificate No. (cURus) E312083

Connection data


Wire connection method Plug-in connection

Classifications

ETIM 8.0	EC002586	ETIM 9.0	EC002586
ETIM 10.0	EC002586	ECLASS 14.0	27-37-16-92
ECLASS 15.0	27-37-16-92		

Drawings

Wiring diagram

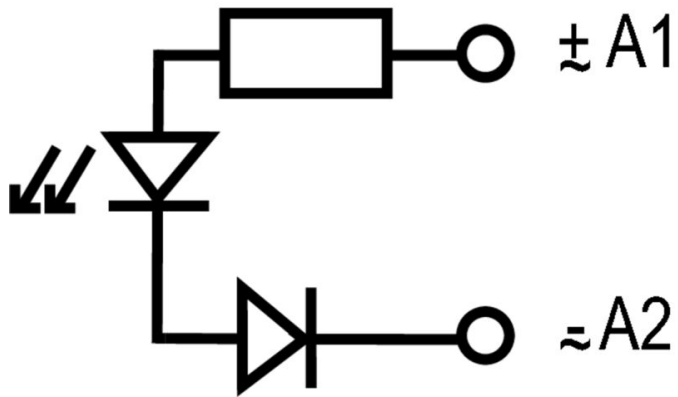

Dimensional drawing

