

**KLIPPON POK1 2M16AB CSS**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

**General ordering data**

Version	Housing with threaded hole, 75 x 80 x 56.5, Glass fibre-reinforced polyester, Drill holes side A: 2 x M16x1.5, Drill holes side B: 2 x M16x1.5
Order No.	<a href="#">8000004160</a>
Type	KLIPPON POK1 2M16AB CSS
GTIN (EAN)	4032248986231
Qty.	1 items

## KLIPPON POK1 2M16AB CSS

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Technical data

### Approvals

Approvals



ROHS Conform

### Dimensions and weights

Depth	56.5 mm	Depth (inches)	2.2244 inch
Height	75 mm	Height (inches)	2.9527 inch
Width	80 mm	Width (inches)	3.1496 inch
Net weight	265 g		

### Environmental Product Compliance

RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	6c
REACH SVHC	Lead 7439-92-1
SCIP	c0b142f1-4049-4b95-bbc3-9959a2d3b09c

### Material data

Surface finish	untreated, polished	Basic material	Glass fibre-reinforced polyester
----------------	---------------------	----------------	----------------------------------

### General data

Colour	Silver grey	Protection degree	IP66, IP67
Colour chart (similar)	RAL 7001		

### Assembly properties

Adjacent	No
----------	----

### Housing

Basic material	Glass fibre-reinforced polyester	Assembled to fit rail	<a href="#">KL SET 6A4 S</a>
Drill holes side C	none	Drill holes side D	none
Drill holes side A	2 x M16x1.5	Unassembled to fit rail	<a href="#">TS15 68 KLIPPON POK1 CSS</a>
Drill holes side B	2 x M16x1.5		

### Standard features

Reference product	<a href="#">KLIPPON POK 080806</a>
-------------------	------------------------------------



### Classifications

ETIM 8.0	EC000261	ETIM 9.0	EC000261
ETIM 10.0	EC000261	ECLASS 14.0	27-18-01-01
ECLASS 15.0	27-18-01-01		

**KLIPPON POK1 2M16AB CSS**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

**Drawings**

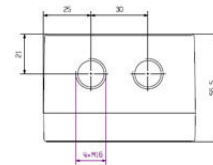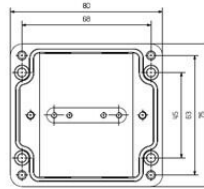

**KLIPPON POK1 2M16AB CSS**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

**Accessories**

[www.weidmueller.com](http://www.weidmueller.com)

**Plastic blanking plugs Ex e/i 7 Joule**

In addition to cable glands for a wide range of applications, the product portfolio is rounded off by plugs, pressure compensation elements, adaptors and the corresponding accessories such as locknuts, sealing rings, flat washers and earthing rings.

**General ordering data**

Type	VP M16 EX SI 7J	Version
Order No.	<a href="#">2066720000</a>	VPK EX 7J (Ex blanking plug, plastic, 7J), Blanking plug, in closed
GTIN (EAN)	4050118415438	state, M 16, 12 mm, IP54, IP66, IP67, IP68 - 5 bar (30 min.),
Qty.	100 ST	Polyamide 6