


FP ENC SM 27/27 K W017

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

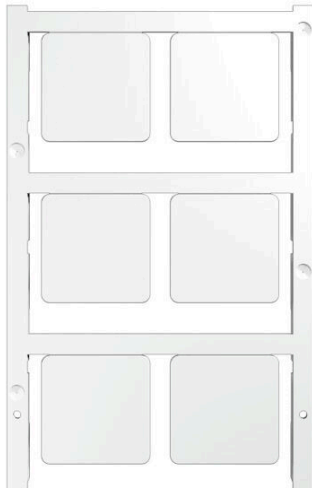

Extensive range of accessories for the FieldPower® boxes.
Cable seals, terminal rails, locking elements and much more.

General ordering data

Version	Device markers, Polyamide
Order No.	8000042927
Type	FP ENC SM 27/27 K W017
GTIN (EAN)	4050118664157
Qty.	2 items

FP ENC SM 27/27 K W017

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Width	27 mm	Width (inches)	1.063 inch
Net weight	2.48 g		

Temperatures

Storage temperature		Operating temperature	
Operating temperature range	-40...100 °C		

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Global

Colour	white	Product type	Device markers
Type	FP ENC SM 27/27 K W017	Order No.	8000042927
GTIN (EAN)	4050118664157	Descriptive text	Gerätemarkierer, MultiCard, selbstklebend, Höhe x Breite: 27 x 27 mm, Werkstoff: Polyamid 66, Brennbarkeitsklasse nach UL 94: V-2, Halogene: Nein, Farbe: weiß, Bedruckung "heiße Oberfläche"

General data

Adhesive	Double-sided adhesive tape	Type of printing	Symbols
Printing method	MC Laser	Version	Self-adhesive
Width	27 mm	UL 94 flammability rating	V-2
Operating temperature range, max.	100 °C	Operating temperature range, min.	-40 °C
Colour	white	Halogen	No
Basic material	Polyamide	Colour of printing	black, yellow
Number of markers per combination	1 MultiCard = Gerätemarkierer	Operating temperature range	-40...100 °C

Device markers

Halogen	No
---------	----

General specifications

Silicone	No	Halogen	No
Basic material	Polyamide	Colour	white
UL 94 flammability rating	V-2		

General data

Basic material	Polyamide	Halogen	No
Silicone	No	Colour	white
UL 94 flammability rating	V-2	Adhesive	Double-sided adhesive tape
Colour of printing	black, yellow	Number of markers per combination	1

FP ENC SM 27/27 K W017

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Technical data

Printing method	MC Laser	Type of printing	Symbols
Version	Self-adhesive		

Classifications

ETIM 8.0	EC001288	ETIM 9.0	EC001288
ETIM 10.0	EC001288	ECLASS 14.0	27-28-11-04
ECLASS 15.0	27-28-11-04		

Drawings



FP ENC SM 27/27 K W017

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Complementary products



SM is a MultiCard marker for labelling control and signalling devices. The tags are clipped into the carriers or attached by means of the adhesive film already fitted to them. Customised tags can be created with the PrintJet CONNECT or Plotter marking systems.

- Users can quickly produce tags to suit their needs
- No need to stock expensive standard tags
- Highly resistant printing quality when using the PrintJet as a substitute for engraving
- For extreme demands, we recommend the ETO SM protective film
- Holders can be used for the 22-mm or 30-mm-diameter push-buttons from Siemens, ABB, Moeller and Télémécanique

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

Type	ETO SM 27/27	Version	
Order No.	1805840000	SwitchMark, Protective cap, 27 x 27 mm, Transparent	
GTIN (EAN)	4032248273577		
Qty.	10 ST		