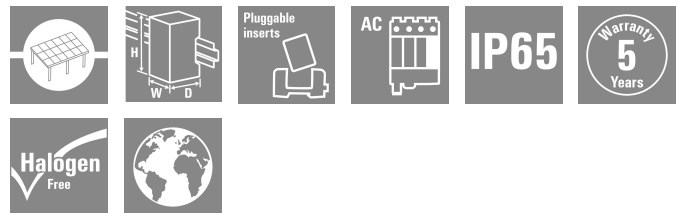


PV 40401S2V1C1A1ES**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Your best option for AC protection.

Designed to work with different string inverters, Weidmüller has developed this standard configurations of AC combiner boxes based upon recurring customer requirements.

Depending on the version, the combiner boxes can contain fuses and surge protection. These combiner boxes are specially designed for major string inverter manufacturers worldwide.

General ordering data

Version	Photovoltaics, Assembled enclosure, Combiner Box, AC voltage version, With fuse holder, Surge protection I, Cable gland, String Inverter
Order No.	8000069107
Type	PV 40401S2V1C1A1ES
GTIN (EAN)	4064675331414
Qty.	1 items

PV 40401S2V1C1A1ES

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS Conform

Dimensions and weights

Depth	350 mm	Depth (inches)	13.7795 inch
Height	1056 mm	Height (inches)	41.5747 inch
Width	852 mm	Width (inches)	33.5432 inch
Net weight	38393.34 g		

Temperatures

Ambient temperature -20 °C...50 °C

Environmental Product Compliance

RoHS Compliance Status Compliant
 REACH SVHC Lead 7439-92-1

Rated data IEC / EN

Rated current	106 A	Voltage type	AC
Fuse protection	125 A gG	Operating voltage	400 V
Suitable for	Photovoltaics	Standards	IEC 61439-2 ed 2.0, EN 61439-2:2011

AC electrical properties

Rated voltage	400 V AC	Surge protection AC side	480V AC, type I, I _{max} = 50kA, U _p ≤ 2.1kV, without auxiliary contact
Earthing	Directly at the VPU		

AC inputs

Cable version	regular	Number of AC inputs	4
---------------	---------	---------------------	---

AC outputs

AC output cable connection type	Screw connection, M12	Number of AC outputs	1
---------------------------------	-----------------------	----------------------	---

Guarantee

Time interval 5 years

General data

Standards	IEC 61439-2 ed 2.0, EN 61439-2:2011	Protection degree	IP65
Installation location	Protected outdoor area (>1 km from sea)		

PV 40401S2V1C1A1ES**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Technical data****Classifications**

ETIM 8.0	EC003857	ETIM 9.0	EC003857
ETIM 10.0	EC003857	ECLASS 14.0	22-57-02-92
ECLASS 15.0	22-57-02-92		

Drawings

