

KEBXHS406020S4B1 AK

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com



Klippon® EBx HS stainless steel enclosures, where the lid is fixed by Hinge and Screws, are offered as high quality products with leading performance characteristics in oil and chemistry hazardous industry. It is certified and complied with the international standards - like ATEX and IECEx approval.

General ordering data

Version	Klippon EBx HS (Essential Box Ex - Hinge Screw), Empty enclosure, Height: 400 mm, Width: 600 mm, Depth: 200 mm, Gland plates: Bottom, Basic material: Stainless steel 1.4404 (316L), Brushed, silver
Order No.	8000071022
Type	KEBXHS406020S4B1 AK
GTIN (EAN)	4064675385028
Qty.	1 items
Local product	Only available in certain countries

KEBXHS406020S4B1 AK

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS Conform

General ordering data

Local product Only available in certain countries

Dimensions and weights

Depth	200 mm	Depth (inches)	7.874 inch
Height	400 mm	Height (inches)	15.748 inch
Width	600 mm	Width (inches)	23.622 inch
Mounting dimension - height	360 mm	Mounting dimension - width	560 mm
Net weight	13412.78 g		

Temperatures

Operating temperature -55 °C...135 °C

Environmental Product Compliance

RoHS Compliance Status Compliant without exemption
 REACH SVHC No SVHC above 0.1 wt%

Cable glands, left

M63	3	M75	3
M12	180	M50	8
M16	87	M32	21
M25	36	M20	58
M40	11		

Cable glands, right

M25	36	M63	3
M75	3	M16	87
M40	11	M50	8
M32	21	M20	58
M12	180		

Cable glands, top/bottom

M20	74	M12	217
M63	6	M40	18
M32	22	M25	45
M50	7	M75	5
M16	115		

KEBXHS406020S4B1 AK

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Certificate numbers enclosure

Declaration of Conformity No. (DoC LVD)	DE PS265X 210819 001ISS01	Attestation of Conformity No. (AoC)	DE PS265x 210819 000ISS01
Certificate no. empty enclosure (INMETRO)	LMP 21.0601U	Certificate no. Terminal Box (ATEX)	IBExU 21ATEX 1017 X
Certificate no. empty enclosure (ATEX)	IBExU 21ATEX 1016 U	Certificate no. Terminal Box (INMETRO)	LMP 21.0602X
Certificate no. Terminal Box (IECEX)	IECEX IBE 21.0012	Certificate no. empty enclosure (IECEX)	IECEX IBE 21.0006U
Approval conditions	ATEX, IECEX, INMETRO		

General information

Material thickness of cover	1.5 mm	Material thickness of flange	3 mm
Material thickness	1.5 mm	Operating temperature, max.	135 °C
Operating temperature, min.	-55 °C	Lid attachment	M6 hex-head slotted screws SW10 + hinges
Standards	EN 60079-0, IEC 60079-0, EN 60079-7, IEC 60079-7, EN 60079-11, IEC 60079-11, EN 60079-31, IEC 60079-31	Surface finish	Brushed
Impact resistance	7 J ATEX version, 10 J version standard	AF size	10 mm
Protection degree	IP66	Basic material	Stainless steel 1.4404 (316L)
Seal material	Silicone (cover + flange)	Torque for lid screws	2.5 Nm
Integral fixing	4, 6 or 9 stud bolts M6 inner (female) thread	Enclosure attachment	4 or 6, M6 blind thread hole on backside; optionally via additional mounting feet
Flange plate mounting	M6 hexagonal head screws 10 SW	Protection class (UL)	Type 1, Type 4, Type 4X
Number of lid screws	2	Gland plates	Bottom
Access opening: width	543.6 mm	Opening angle lid	125.00 °
Flange plate	Yes	Max. payload	24 kg
Lid	Yes	Access opening: height	349.6 mm
Position PE bolts	Enclosure side C	Areas of use	Chemical industry, Explosive risk zone, Oil and gas industry, Onshore, Process industry, Building systems and technology, Machine construction, Packaging industry

Housing earth

Earth, enclosure, internal	Welded-on M6 stainless-steel earth stud in enclosure body and lid.
----------------------------	--

horizontal assembly

WDU 10 / ZDU 10	4x49	WDU 16 / ZDU 16	4x41
WDU 2,5 / ZDU 2,5 / IDU 2,5	4x98	WDU 35 / ZDU 35	4x30
WDU 4 / ZDU 4	4x82	WDU 6 / ZDU 6	4x61

vertical assembly

WDU 10 / ZDU 10	6x30	WDU 16 / ZDU 16	6x25
WDU 2,5 / ZDU 2,5 / IDU 2,5	6x61	WDU 35 / ZDU 35	6x18
WDU 4 / ZDU 4	6x51	WDU 6 / ZDU 6	6x38

Creation date 05.03.2026 02:27:35 MEZ

Catalogue status / Drawings

KEBXHS406020S4B1 AK

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Technical data

Important note

Product information All articles with M6 threaded rivet as standard; UL variants with M10 earth bolt on request

Classifications

ETIM 8.0	EC002503	ETIM 9.0	EC002503
ETIM 10.0	EC002503	ECLASS 14.0	27-18-05-02
ECLASS 15.0	27-18-05-02		


KEBXHS406020S4B1 AK

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

Drawings

www.weidmueller.com

VIEW WITHOUT COVER, SEAL AND SCREW

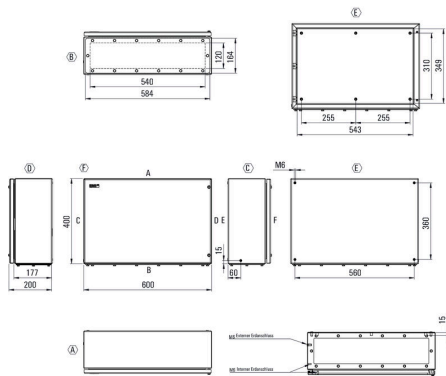

KEBXHS406020S4B1 AK

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Mounting plates



Mounting plates, with and without hole patterns, for longitudinal and transverse mounting of DIN mounting rails or components directly onto the mounting plate.

General ordering data

Type	KEB MOPL 4060 MSZN	Version
Order No.	8000074174	Klippon EB (Essential Box), Mounting plate, Height: 340 mm, Width: 540 mm, Depth: 12 mm, Basic material: Sheet steel, galvanized, silver
GTIN (EAN)	4064675425199	
Qty.	1 ST	
Type	KEB MOPL 4060 S2N H	Version
Order No.	8000074320	Klippon EB (Essential Box), Mounting plate, Height: 340 mm, Width: 540 mm, Depth: 12 mm, Basic material: Stainless steel 1.4301 (304), untreated, silver
GTIN (EAN)	4064675425298	
Qty.	1 ST	

Document holders



Document holders for the proper storage of documents in the enclosure.

General ordering data

Type	DOHA KEB A4 S4B R	Version
Order No.	8000075809	Klippon EB (Essential Box), Enclosures, Riveted, Height: 175 mm, Depth: 20 mm, Basic material: Stainless steel 1.4404, silver
GTIN (EAN)	4064675425656	
Qty.	1 ST	
Type	DOHA KEB A5 S4B R	Version
Order No.	8000075808	Klippon EB (Essential Box), Enclosures, Riveted, Height: 125 mm, Depth: 20 mm, Basic material: Stainless steel 1.4404, silver
GTIN (EAN)	4064675425649	
Qty.	1 ST	
Type	DOHA KEB A6 S4B R	Version
Order No.	8000075807	Klippon EB (Essential Box), Enclosures, Riveted, Height: 95 mm, Depth: 20 mm, Basic material: Stainless steel 1.4404, silver
GTIN (EAN)	4064675425359	
Qty.	1 ST	

KEBXHS406020S4B1 AK

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Mounting feet



With the additionally available mounting feet, the enclosures can also be mounted from outside the enclosure.

General ordering data

Type	KEB MOFT SMALL S4 SET	Version
Order No.	2660200318	Klippon EB (Essential Box), Mounting foot, Height: 38 mm, Width: 55
GTIN (EAN)	4064675275695	mm, Depth: 10.5 mm, Basic material: Steel, untreated, silver
Qty.	1 ST	

Spacer



Stainless steel spacers in three lengths to increase the distance between the mounting rails or DIN rails and the rear wall of the enclosure.

General ordering data

Type	SP M6 15 MSZN	Version
Order No.	3896100000	Klippon EB (Essential Box), Spacer, Height: 11.2 mm, Width: 10 mm,
GTIN (EAN)	4008190857851	Depth: 15 mm, Basic material: Steel, silver
Qty.	2 ST	
Type	SP M6 20 MSZN	Version
Order No.	3896200000	Klippon EB (Essential Box), Spacer, Height: 11.2 mm, Width: 10 mm,
GTIN (EAN)	4008190850234	Depth: 20 mm, Basic material: Steel, silver
Qty.	2 ST	
Type	SP M6 30 MSZN	Version
Order No.	3896300000	Klippon EB (Essential Box), Spacer, Height: 11.2 mm, Width: 10 mm,
GTIN (EAN)	4008190850241	Depth: 30 mm, Basic material: Steel, silver
Qty.	2 ST	

KEBXHS406020S4B1 AK

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Type label holder



There are a variety of designed label holders available for prominent display as required and for additional nameplates as needed.

General ordering data

Type	TPSDHA KEB 100X25 S4B R	Version
Order No.	8000075818	Klippon EB (Essential Box), Enclosures, Riveted, Height: 25 mm,
GTIN (EAN)	4064675425632	Width: 141 mm, Depth: 16.5 mm, Basic material: Stainless steel
Qty.	1 ST	1.4404 (316L), Brushed, silver

Type	TPSDHA KEB 130X50 S4B R	Version
Order No.	8000075816	Klippon EB (Essential Box), Enclosures, Riveted, Height: 50 mm,
GTIN (EAN)	4064675425366	Width: 171 mm, Depth: 16.5 mm, Basic material: Stainless steel
Qty.	1 ST	1.4404 (316L), Brushed, silver

Mounting plates



Mounting plates, with and without hole patterns, for longitudinal and transverse mounting of DIN mounting rails or components directly onto the mounting plate.

General ordering data

Type	GFSC M5X10 TX20 SET	Version
Order No.	1274150000	Klippon EB (Essential Box), Mounting screw, Height: 13.3 mm, Width:
GTIN (EAN)	4050118063820	8.5 mm, Depth: 8.5 mm, Basic material: Steel, galvanized, galvanic
Qty.	1 ST	zinc plated and passivated, silver

KEBXHS406020S4B1 AK

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Installation material



Integrate, expand and customise - the perfect supplement to every application

The fully structured range of system accessories for the new Klippon® TB enclosure series allows you to easily adapt the enclosures to meet the specific requirements of every application.

Mounting hardware kits

Mounting hardware kits are available for quick and easy installation of type label holders, document holders and rain hoods.

The label fastening set – SD is required to install a plastic (Trafolyte) ID or type label. With the aid of this set can you mount the ID or type label directly on the enclosure cover. The label fastening set has been specially developed for this purpose. Only by using this fastening set can you ensure that there will be no leaks into the enclosure or damage to the label.

The universal fastening set – TPSD has been developed to enable secure and quick installation of type label holders, rain covers or document holders, for example. By using this fastening set, the risk of leaks can be minimised, if not avoided.

General ordering data

Type	LKSC M6X8 A2 TX30	Version	
Order No.	2704960000	Klippon TB (Terminal Box), Set of fixings, Height: 11.3 mm, Width: 13.6 mm, Depth: 13.6 mm, Basic material: Stainless steel, rust-proof, untreated, silver	
GTIN (EAN)	4050118753196		
Qty.	500 ST		

Slotted screwdriver



VDE insulated screwdriver sets, for working on live parts up to 1000 V AC and 1500 V DC, DIN EN 60900. IEC 900. Each piece is "GS" safety tested. Blade made from fully hardened, high-alloy chromium-vanadium-molybdenum steel, gun-metal finish.

General ordering data

Type	SDIS SLIM 1.2X6.5X150	Version	
Order No.	2749640000	Mounting tool, Blade width (B): 6.5 mm, Blade length: 150 mm, Blade thickness (A): 1.2 mm	
GTIN (EAN)	4050118896381		
Qty.	1 ST		