

**KEBIHS404020S2N1 AL****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

The new Klippon® EBi enclosure series has been specially designed for use in industrial environments. It reliably meets all requirements for use in harsh environments and is characterised by attractive performance features. The cost-effective stainless steel enclosures allow a very economical calculation and are also suitable for projects with a limited budget. In addition to Klippon® EBi for industrial applications, there is Klippon® EBx for hazardous areas. Enclosures with cULus approvals are available on request.

**General ordering data**

Version	Klippon EBi HS (Essential Box industrial - Hinged Screws), Enclosures, Height: 400 mm, Width: 400 mm, Depth: 200 mm, Gland plates: Bottom, Basic material: Stainless steel 1.4301 (304), untreated, silver
Order No.	<a href="#">8000090354</a>
Type	KEBIHS404020S2N1 AL
GTIN (EAN)	4064675855675
Qty.	1 items

## KEBIHS404020S2N1 AL

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Technical data

### Approvals

Approvals



ROHS Conform

### Dimensions and weights

Depth	200 mm	Depth (inches)	7.874 inch
Height	400 mm	Height (inches)	15.748 inch
Width	400 mm	Width (inches)	15.748 inch
Net weight	9515.05 g		

### Temperatures

Operating temperature -40 °C...85 °C

### Environmental Product Compliance

RoHS Compliance Status Compliant without exemption  
 REACH SVHC No SVHC above 0.1 wt%

### Cable glands, left

M63	3	M12	96
M50	4	M16	65
M32	21	M25	24
M20	40	M40	10

### Cable glands, right

M25	24	M63	3
M16	65	M40	10
M50	4	M32	21
M20	40	M12	96

### Cable glands, top/bottom

M20	30	M12	80
M63	3	M40	10
M32	12	M25	24
M50	4	M16	48

### Certificate numbers enclosure

Declaration of Conformatiy No. (DoC LVD) DE PS2650 220428  
 001ISS01

### General information

Material thickness of cover	1.5 mm	Material thickness of flange	3 mm
Material thickness of enclosure	1.5 mm	Silicone	No

**KEBIHS404020S2N1 AL**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

Operating temperature, max.	85 °C	Operating temperature, min.	-40 °C
Lid attachment	M5 hexagonal screw with slot and 10mm distance across flats + hinge	Surface finish	untreated
Impact resistance	10 J version standard	Protection degree	IP66
Basic material	Stainless steel 1.4301 (304)	Seal material	Chloroprene
Enclosure attachment	Installation through the housing rear wall	Note: protection class	IP protection is only given after wall mounting using the enclosed sealing washers.
Gland plates	Bottom	Flange plate	Yes

**horizontal assembly**

WDU 10 / ZDU 10	2x30	WDU 16 / ZDU 16	2x24
WDU 2,5 / ZDU 2,5 / IDU 2,5	3x59	WDU 35 / ZDU 35	1x11
WDU 4 / ZDU 4	3x49	WDU 6 / ZDU 6	2x37

**vertical assembly**

WDU 10 / ZDU 10	2x30	WDU 16 / ZDU 16	2x24
WDU 2,5 / ZDU 2,5 / IDU 2,5	3x59	WDU 35 / ZDU 35	1x18
WDU 4 / ZDU 4	3x49	WDU 6 / ZDU 6	2x37

**Classifications**


ETIM 8.0	EC000261	ETIM 9.0	EC000261
ETIM 10.0	EC000261	ECLASS 14.0	27-18-01-01
ECLASS 15.0	27-18-01-01		

**KEBIHS404020S2N1 AL**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

**Drawings**

www.weidmueller.com

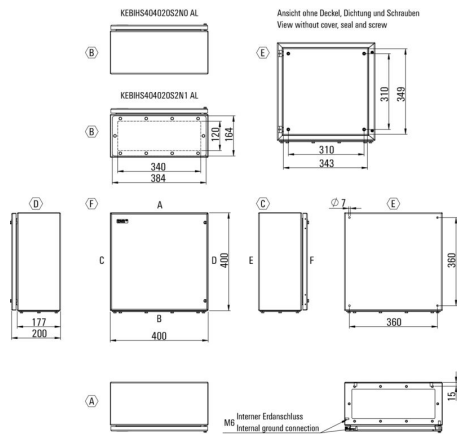

## KEBIHS404020S2N1 AL

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

### Mounting plates



Mounting plates, with and without hole patterns, for longitudinal and transverse mounting of DIN mounting rails or components directly onto the mounting plate.

### General ordering data

Type	KEB MOPL 4040 MSZN	Version	
Order No.	<a href="#">8000074173</a>	Klippon EB (Essential Box), Mounting plate, Height: 340 mm, Width: 340 mm, Depth: 1.5 mm, Basic material: Sheet steel, galvanized,	
GTIN (EAN)	4064675425182	silver	
Qty.	1 ST		
Type	KEB MOPL 4040 S2N H	Version	
Order No.	<a href="#">8000074319</a>	Klippon EB (Essential Box), Mounting plate, Height: 340 mm, Width: 340 mm, Depth: 1.5 mm, Basic material: Stainless steel 1.4301	
GTIN (EAN)	4064675425281	(304), untreated, silver	
Qty.	1 ST		

### Document holders



Document holders for the proper storage of documents in the enclosure.

### General ordering data

Type	DOHA KEB A4 S4B R	Version	
Order No.	<a href="#">8000075809</a>	Klippon EB (Essential Box), Enclosures, Riveted, Height: 175 mm, Depth: 20 mm, Basic material: Stainless steel 1.4404, silver	
GTIN (EAN)	4064675425656		
Qty.	1 ST		
Type	DOHA KEB A5 S4B R	Version	
Order No.	<a href="#">8000075808</a>	Klippon EB (Essential Box), Enclosures, Riveted, Height: 125 mm, Depth: 20 mm, Basic material: Stainless steel 1.4404, silver	
GTIN (EAN)	4064675425649		
Qty.	1 ST		
Type	DOHA KEB A6 S4B R	Version	
Order No.	<a href="#">8000075807</a>	Klippon EB (Essential Box), Enclosures, Riveted, Height: 95 mm, Depth: 20 mm, Basic material: Stainless steel 1.4404, silver	
GTIN (EAN)	4064675425359		
Qty.	1 ST		

## KEBIHS404020S2N1 AL

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

## Mounting feet



With the additionally available mounting feet, the enclosures can also be mounted from outside the enclosure.

## General ordering data

Type	KEB MOFT SMALL S4 SET	Version
Order No.	<a href="#">2660200318</a>	Klippon EB (Essential Box), Mounting foot, Height: 38 mm, Width: 55
GTIN (EAN)	4064675275695	mm, Depth: 10.5 mm, Basic material: Steel, untreated, silver
Qty.	1 ST	

## Spacer



Stainless steel spacers in three lengths to increase the distance between the mounting rails or DIN rails and the rear wall of the enclosure.

## General ordering data

Type	SP M6 15 MSZN	Version
Order No.	<a href="#">3896100000</a>	Klippon EB (Essential Box), Spacer, Height: 11.2 mm, Width: 10 mm,
GTIN (EAN)	4008190857851	Depth: 15 mm, Basic material: Steel, silver
Qty.	2 ST	
Type	SP M6 20 MSZN	Version
Order No.	<a href="#">3896200000</a>	Klippon EB (Essential Box), Spacer, Height: 11.2 mm, Width: 10 mm,
GTIN (EAN)	4008190850234	Depth: 20 mm, Basic material: Steel, silver
Qty.	2 ST	
Type	SP M6 30 MSZN	Version
Order No.	<a href="#">3896300000</a>	Klippon EB (Essential Box), Spacer, Height: 11.2 mm, Width: 10 mm,
GTIN (EAN)	4008190850241	Depth: 30 mm, Basic material: Steel, silver
Qty.	2 ST	

**KEBIHS404020S2N1 AL**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Accessories**

**Type label holder**



There are a variety of designed label holders available for prominent display as required and for additional nameplates as needed.

**General ordering data**

Type	TPSDHA KEB 100X25 S4B R	Version
Order No.	<a href="#">8000075818</a>	Klippon EB (Essential Box), Enclosures, Riveted, Height: 25 mm,
GTIN (EAN)	4064675425632	Width: 141 mm, Depth: 16.5 mm, Basic material: Stainless steel
Qty.	1 ST	1.4404 (316L), Brushed, silver

Type	TPSDHA KEB 130X50 S4B R	Version
Order No.	<a href="#">8000075816</a>	Klippon EB (Essential Box), Enclosures, Riveted, Height: 50 mm,
GTIN (EAN)	4064675425366	Width: 171 mm, Depth: 16.5 mm, Basic material: Stainless steel
Qty.	1 ST	1.4404 (316L), Brushed, silver

**Mounting plates**



Mounting plates, with and without hole patterns, for longitudinal and transverse mounting of DIN mounting rails or components directly onto the mounting plate.

**General ordering data**

Type	GFSC M5X10 TX20 SET	Version
Order No.	<a href="#">1274150000</a>	Klippon EB (Essential Box), Mounting screw, Height: 13.3 mm, Width:
GTIN (EAN)	4050118063820	8.5 mm, Depth: 8.5 mm, Basic material: Steel, galvanized, galvanic
Qty.	1 ST	zinc plated and passivated, silver

## KEBIHS404020S2N1 AL

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## Installation material



Integrate, expand and customise - the perfect supplement to every application

The fully structured range of system accessories for the new Klippon® TB enclosure series allows you to easily adapt the enclosures to meet the specific requirements of every application.

Mounting hardware kits

Mounting hardware kits are available for quick and easy installation of type label holders, document holders and rain hoods.

The label fastening set – SD is required to install a plastic (Trafolyte) ID or type label. With the aid of this set can you mount the ID or type label directly on the enclosure cover. The label fastening set has been specially developed for this purpose. Only by using this fastening set can you ensure that there will be no leaks into the enclosure or damage to the label.

The universal fastening set – TPSD has been developed to enable secure and quick installation of type label holders, rain covers or document holders, for example. By using this fastening set, the risk of leaks can be minimised, if not avoided.

## General ordering data

Type	LKSC M6X8 A2 TX30	Version	
Order No.	<a href="#">2704960000</a>	Klippon TB (Terminal Box), Set of fixings, Height: 11.3 mm, Width: 13.6 mm, Depth: 13.6 mm, Basic material: Stainless steel, rust-proof, untreated, silver	
GTIN (EAN)	4050118753196		
Qty.	500 ST		

## Slotted screwdriver



VDE insulated screwdriver sets, for working on live parts up to 1000 V AC and 1500 V DC, DIN EN 60900. IEC 900. Each piece is "GS" safety tested. Blade made from fully hardened, high-alloy chromium-vanadium-molybdenum steel, gun-metal finish.

## General ordering data

Type	SDIS SLIM 1.2X6.5X150	Version	
Order No.	<a href="#">2749640000</a>	Mounting tool, Blade width (B): 6.5 mm, Blade length: 150 mm, Blade thickness (A): 1.2 mm	
GTIN (EAN)	4050118896381		
Qty.	1 ST		