


## AP RF 80 LI 2025

**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

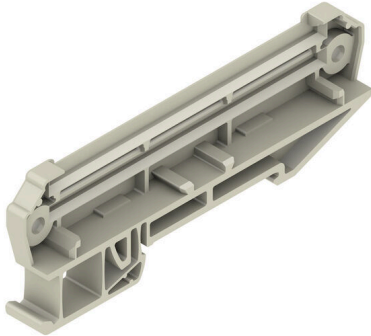

The RS 100 Profi offers you a flexible solution for your mounting needs, as both DIN rail mounting and wall mounting are possible. This versatility facilitates integration into different environments and applications. The housing can be used for the Eurocard PCB standard. The profile can be cut to size so that you can adapt it precisely to your specific requirements. For particularly heavy components, additional locking feet can be used to improve stability and thus increase the safety of your installation.

Another practical feature is the option of using a cover profile to protect large components.

### General ordering data

|            |  |
|------------|--|
| Version    | End plate, RS 80 Pebble grey, End plate DIN mounting rail left, Width: 30 mm |
| Order No.  | <a href="#">8156210000</a>   |
| Type       | AP RF 80 LI 2025   |
| GTIN (EAN) | 4008190978198  |
| Qty.       | 20 items   |

## AP RF 80 LI 2025

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Technical data

### Approvals

|      |         |
|------|---------|
| ROHS | Conform |
|------|---------|

### Dimensions and weights

|            |         |                 |             |
|------------|---------|-----------------|-------------|
| Depth      | 9 mm    | Depth (inches)  | 0.3543 inch |
| Height     | 86.4 mm | Height (inches) | 3.4016 inch |
| Width      | 30 mm   | Width (inches)  | 1.1811 inch |
| Net weight | 5.95 g  |                 |             |

### Environmental Product Compliance

|                        |                             |
|------------------------|-----------------------------|
| RoHS Compliance Status | Compliant without exemption |
| REACH SVHC             | No SVHC above 0.1 wt%       |

### Material data

|                           |       |                                  |           |
|---------------------------|-------|----------------------------------|-----------|
| UL 94 flammability rating | V-0   | Insulating material              | PA 66     |
| Insulating material group | I     | Surface finish                   | untreated |
| Basic material            | PA 66 | Comparative Tracking Index (CTI) | 600 ≤ CTI |

### General data

|                        |             |                      |                         |
|------------------------|-------------|----------------------|-------------------------|
| Colour                 | Pebble grey | Protection degree    | IP20 in installed state |
| Colour chart (similar) | RAL 7032    | Encapsulation option | No                      |

### Classifications

|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 8.0    | EC001031    | ETIM 9.0    | EC002779    |
| ETIM 10.0   | EC002779    | ECLASS 14.0 | 27-19-06-02 |
| ECLASS 15.0 | 27-19-06-02 |             |             |

AP RF 80 LI 2025

Weidmüller Interface GmbH & Co. KG  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

Drawings

[www.weidmueller.com](http://www.weidmueller.com)

RAIL MOUNTING  
WITH LOCKING FOOT

