

## FBK 10/200 RK

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)



Similar to illustration

The pre-assembled control cables have pluggable 10- or 40-pole socket blocks according to IEC 603/1 DIN 41 651. They can be used to connect the PLC front adapter to the active or passive Weidmüller interfaces. They are available in different lengths.

### General ordering data

Version	Pre-assembled cable, FBK, FLAT CABLE CONECTOR HE10 10P
Order No.	<a href="#">8235380000</a>
Type	FBK 10/200 RK
GTIN (EAN)	4008190264604
Qty.	1 items

**Technical data**

**Approvals**

ROHS Conform

**Dimensions and weights**

Net weight 127 g

**Temperatures**

Storage temperature -10...70 °C Operating temperature

**Environmental Product Compliance**

RoHS Compliance Status Compliant without exemption  
 REACH SVHC No SVHC above 0.1 wt%

**General Data**

Cable length	2 m	Suitable for	Digital signals
Basic material	PVC	Cable	Cable LiYY
Interface connector	FLAT CABLE CONECTOR HE10 10P	Number of poles, min.	10-pole
Connector PLC side	FLAT CABLE CONECTOR HE10 10P	Wire cross-section	0.14 mm <sup>2</sup>

**Electrical Data**

Total current, max.	3 A	Permissible current strength per path, max.	1 A
Rated voltage	< 50 V AC, ≤ 50 V DC	Resistance	55 mΩ/m

**Classifications**

ETIM 8.0	EC000237	ETIM 9.0	EC000237
ETIM 10.0	EC000237	ECLASS 14.0	27-24-22-20
ECLASS 15.0	27-24-22-20		

## FBK 10/200 RK

**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

## Accessories

### Interfaces for output signals



The RS F40 or RS F10 interface elements (for 32 or 8 signals) enable a relay to be used to isolate signals coming from the PLC with sensors and field actuators. The main characteristics are:

- Tension-clamp or screw connection system
- Signals grouped according to bytes.
- Extremely compact modules in RS 45 profile section for installation on standard TS35 mounting rail.

#### General ordering data

Type	RS F40 16RS OUT 24VDC	Version
Order No.	<a href="#">8224181001</a>	RCL314024, Screw connection
GTIN (EAN)	4032248063338	
Qty.	1 ST	

Type	RS F40 16RS OUT 24VDC E	Version
Order No.	<a href="#">8224191001</a>	RCL314024, Screw connection
GTIN (EAN)	4032248159888	
Qty.	1 ST	

### Direct input/output digital interfaces




Passive RS F40 or RS F10 interface elements for 32 or 8 signals: these enable an efficient connection of peripherals (sensors and actuators) to the input/output modules of the PLC using pre-assembled cables. The main characteristics are:

- Tension-clamp or screw connection system
- Signals grouped according to bytes.
- 1-, 2- or 3-wire technology.
- Extremely compact modules in RS 45 profile section for installation on standard TS35 mounting rail.

#### General ordering data

Type	RS F10 I/O8 LD LPK2	Version
Order No.	<a href="#">8224260000</a>	Interface, RSF, 1-wire, Screw connection
GTIN (EAN)	4008190208127	
Qty.	1 ST	

### Interfaces for output signals

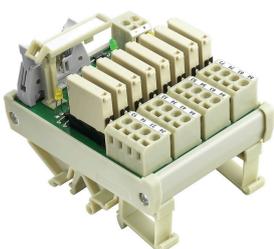

The RS F40 or RS F10 interface elements (for 32 or 8 signals) enable a relay to be used to isolate signals coming from the PLC with sensors and field actuators. The main characteristics are:

- Tension-clamp or screw connection system
- Signals grouped according to bytes.
- Extremely compact modules in RS 45 profile section for installation on standard TS35 mounting rail.

## FBK 10/200 RK

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

### General ordering data

Type	RS F10 8R OUT 24VDC	Version	
Order No.	<a href="#">8329800000</a>	DOLD OW5691, Screw connection	
GTIN (EAN)	4008190337216		
Qty.	1 ST		

### Front adapter for PLC S7



The front-panel adapter can be quickly and securely connected to SIEMENS S7 300/400 I/O modules. They offer inexpensive coupling of active and passive interface modules.


- Pre-assembled control cable, 4 x 10 or 1 x 40 poles
- Separate feeding of supply voltage via screw connection terminals
- Isolation of potentials via plug-in cross-connectors.

### General ordering data

Type	SIM S7/400 FB40 2.0M	Version	
Order No.	<a href="#">8335900200</a>		
GTIN (EAN)	4008190915759		
Qty.	1 ST		
Type	SIM S7/400 FB40 2.5M	Version	
Order No.	<a href="#">8335900250</a>	Pre-assembled cable, SIM, Siemens S7-400, 48 P	
GTIN (EAN)	4008190072094		
Qty.	1 ST		
Type	SIM S7/400 FB40 3.0M	Version	
Order No.	<a href="#">8335900300</a>	Pre-assembled cable, SIM, Siemens S7-400, 48 P	
GTIN (EAN)	4032248016426		
Qty.	1 ST		
Type	SIM S7/400 FB4*10 2.0M	Version	
Order No.	<a href="#">8335910200</a>	Pre-assembled cable, SIM, Siemens S7-400, 48 P	
GTIN (EAN)	4008190072773		
Qty.	1 ST		
Type	SIM S7/400 FB4*10 2.5M	Version	
Order No.	<a href="#">8335910250</a>	Pre-assembled cable, SIM, Siemens S7-400, 48 P	
GTIN (EAN)	4008190073213		
Qty.	1 ST		
Type	SIM S7/400 FB4*10 3.0M	Version	
Order No.	<a href="#">8335910300</a>	Pre-assembled cable, SIM, Siemens S7-400, 48 P	
GTIN (EAN)	4008190073497		
Qty.	1 ST		
Type	SIM S7/400 FB4*10 5.0M	Version	
Order No.	<a href="#">8335910500</a>	Pre-assembled cable, SIM, Siemens S7-400, 48 P	
GTIN (EAN)	4008190915704		
Qty.	1 ST		

## Accessories

### Direct input/output digital interfaces

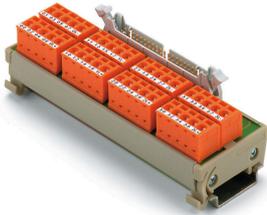

Passive RS F40 or RS F10 interface elements for 32 or 8 signals: these enable an efficient connection of peripherals (sensors and actuators) to the input/output modules of the PLC using pre-assembled cables.

The main characteristics are:

- Tension-clamp or screw connection system
- Signals grouped according to bytes.
- 1-, 2- or 3-wire technology.
- Extremely compact modules in RS 45 profile section for installation on standard TS35 mounting rail.

#### General ordering data

Type	RS F10 I/O8 LMZF	Version
Order No.	<a href="#">8428870000</a>	Interface, RSF, 1-wire, Tension-clamp connection
GTIN (EAN)	4008190030582	
Qty.	1 ST	
Type	RS F40 I/O32 LMZF	Version
Order No.	<a href="#">8428880000</a>	Interface, RSF, 1-wire, Tension-clamp connection
GTIN (EAN)	4008190032210	
Qty.	1 ST	
Type	RS F10 INIT8 LD LMZF	Version
Order No.	<a href="#">8428890000</a>	Interface, RSF, 3-wire, Tension-clamp connection
GTIN (EAN)	4008190032005	
Qty.	1 ST	
Type	RS F40 INIT32 LD LMZF	Version
Order No.	<a href="#">8428900000</a>	Interface, RSF, 3-wire, Tension-clamp connection
GTIN (EAN)	4008190030384	
Qty.	1 ST	
Type	RS F40 INIT32 LMZF	Version
Order No.	<a href="#">8430980000</a>	Interface, RSF, 2-wire, Tension-clamp connection
GTIN (EAN)	4008190036188	
Qty.	1 ST	

### Interfaces for output signals



The RS F40 or RS F10 interface elements (for 32 or 8 signals) enable a relay to be used to isolate signals coming from the PLC with sensors and field actuators.

The main characteristics are:

- Tension-clamp or screw connection system
- Signals grouped according to bytes.
- Extremely compact modules in RS 45 profile section for installation on standard TS35 mounting rail.

#### General ordering data

Type	RS F10 8RS OUT LMZF	Version
Order No.	<a href="#">8430990000</a>	FUJITSU NYP-24WK, Tension-clamp connection
GTIN (EAN)	4008190027551	
Qty.	1 ST	

## FBK 10/200 RK

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

Type	RS F40 32RS OUT LMZF	Version	
Order No.	<a href="#">8431000000</a>		FUJITSU NYP-24WK, Tension-clamp connection
GTIN (EAN)	4008190032753		
Qty.	1 ST		

### Front adapter for PLC S7



The front-panel adapter can be quickly and securely connected to SIEMENS S7 300/400 I/O modules. They offer inexpensive coupling of active and passive interface modules.

- Pre-assembled control cable, 4 x 10 or 1 x 40 poles
- Separate feeding of supply voltage via screw connection terminals
- Isolation of potentials via plug-in cross-connectors.

### General ordering data

Type	SIM S7/300 FB40 2.0M	Version	
Order No.	<a href="#">8433290200</a>		Pre-assembled cable, SIM, Siemens S7-300, 40 P
GTIN (EAN)	4008190094195		
Qty.	1 ST		
Type	SIM S7/300 FB40 2.5M	Version	
Order No.	<a href="#">8433290250</a>		Pre-assembled cable, SIM, Siemens S7-300, 40 P
GTIN (EAN)	4008190097424		
Qty.	1 ST		
Type	SIM S7/300 FB40 3.0M	Version	
Order No.	<a href="#">8433290300</a>		Pre-assembled cable, SIM, Siemens S7-300, 40 P
GTIN (EAN)	4008190113001		
Qty.	1 ST		
Type	SIM S7/300 FB40 5.0M	Version	
Order No.	<a href="#">8433290500</a>		Pre-assembled cable, SIM, Siemens S7-300, 40 P
GTIN (EAN)	4008190120252		
Qty.	1 ST		
Type	SIM S7/300 FB4*10 2.0M	Version	
Order No.	<a href="#">8433310200</a>		Pre-assembled cable, SIM, Siemens S7-300, 40 P
GTIN (EAN)	4008190058494		
Qty.	1 ST		
Type	SIM S7/300 FB4*10 2.5M	Version	
Order No.	<a href="#">8433310250</a>		Pre-assembled cable, SIM, Siemens S7-300, 40 P
GTIN (EAN)	4008190059941		
Qty.	1 ST		
Type	SIM S7/300 FB4*10 3.0M	Version	
Order No.	<a href="#">8433310300</a>		Pre-assembled cable, SIM, Siemens S7-300, 40 P
GTIN (EAN)	4008190064204		
Qty.	1 ST		
Type	SIM S7/300 FB4*10 5.0M	Version	
Order No.	<a href="#">8433310500</a>		Pre-assembled cable, SIM, Siemens S7-300, 40 P
GTIN (EAN)	4008190069032		
Qty.	1 ST		

## Micro interface digital



Specific adapter to be connected to the MICROSERIE RELAYS using a 10-pole flat-cable connector or 15-pole Sub-D connector.

## General ordering data

Type	MI8DO-Z SUB D15S	Version
Order No.	<a href="#">8773570000</a>	IEC 60603/DIN41612 plug-in connectors, Tension-clamp connection
GTIN (EAN)	4032248442102	
Qty.	1 ST	
Type	MI8DI-Z F10 S	Version
Order No.	<a href="#">8773530000</a>	Plug-in connector in acc. with IEC60603-13 / DIN41651, Tension-clamp connection
GTIN (EAN)	4032248442065	
Qty.	1 ST	
Type	MI8DI-Z SUB D15S	Version
Order No.	<a href="#">8773490000</a>	IEC 60603/DIN41612 plug-in connectors, Tension-clamp connection
GTIN (EAN)	4032248442010	
Qty.	1 ST	
Type	MI8DI-S SUB D15S	Version
Order No.	<a href="#">8773460000</a>	IEC 60603/DIN41612 plug-in connectors, Screw connection
GTIN (EAN)	4032248441990	
Qty.	1 ST	
Type	MI8DO-S SUB D15S	Version
Order No.	<a href="#">8773550000</a>	IEC 60603/DIN41612 plug-in connectors, Screw connection
GTIN (EAN)	4032248442089	
Qty.	1 ST	
Type	MI8DO-Z F10 S	Version
Order No.	<a href="#">8773620000</a>	Plug-in connector in acc. with IEC60603-13 / DIN41651, Tension-clamp connection
GTIN (EAN)	4032248442157	
Qty.	1 ST	
Type	MI8DO-S F10 S	Version
Order No.	<a href="#">8773600000</a>	Plug-in connector in acc. with IEC60603-13 / DIN41651, Screw connection
GTIN (EAN)	4032248442133	
Qty.	1 ST	
Type	MI8DI-S F10 S	Version
Order No.	<a href="#">8773510000</a>	Plug-in connector in acc. with IEC60603-13 / DIN41651, Screw connection
GTIN (EAN)	4032248442034	
Qty.	1 ST	

### Pre-assembled control cable



The pre-assembled control cables have pluggable 10- or 40-pole socket blocks according to IEC 603/1 DIN 41 651. They can be used to connect the PLC front adapter to the active or passive Weidmüller interfaces. They are available in different lengths.

### General ordering data

Type	FBK 40/500 RK	Version
Order No.	<a href="#">8235350000</a>	Pre-assembled cable, FBK, FLAT CABLE PLANO HE10 40P
GTIN (EAN)	4008190267759	
Qty.	1 ST	
Type	FBK 40/100 RK	Version
Order No.	<a href="#">8216350000</a>	Pre-assembled cable, FBK, FLAT CABLE PLANO HE10 40P
GTIN (EAN)	4008190190392	
Qty.	1 ST	
Type	FBK 10/500 RK	Version
Order No.	<a href="#">8235440000</a>	Pre-assembled cable, FBK, FLAT CABLE CONECTOR HE10 10P
GTIN (EAN)	4008190264666	
Qty.	1 ST	
Type	FBK 10/400 RK	Version
Order No.	<a href="#">8235420000</a>	Pre-assembled cable, FBK, FLAT CABLE CONECTOR HE10 10P
GTIN (EAN)	4008190264642	
Qty.	1 ST	
Type	FBK 10/350 RK	Version
Order No.	<a href="#">8235410000</a>	Pre-assembled cable, FBK, FLAT CABLE CONECTOR HE10 10P
GTIN (EAN)	4008190264635	
Qty.	1 ST	
Type	FBK 40/300 RK	Version
Order No.	<a href="#">8216390000</a>	Pre-assembled cable, FBK, FLAT CABLE PLANO HE10 40P
GTIN (EAN)	4008190264697	
Qty.	1 ST	
Type	FBK 40/150 RK	Version
Order No.	<a href="#">8216360000</a>	Pre-assembled cable, FBK, FLAT CABLE PLANO HE10 40P
GTIN (EAN)	4008190264673	
Qty.	1 ST	
Type	FBK 40/400 RK	Version
Order No.	<a href="#">8216410000</a>	Pre-assembled cable, FBK, FLAT CABLE PLANO HE10 40P
GTIN (EAN)	4008190264710	
Qty.	1 ST	
Type	FBK 40/200 RK	Version
Order No.	<a href="#">8216370000</a>	Pre-assembled cable, FBK, FLAT CABLE PLANO HE10 40P
GTIN (EAN)	4008190263584	
Qty.	1 ST	
Type	FBK 40/350 RK	Version
Order No.	<a href="#">8216400000</a>	Pre-assembled cable, FBK, FLAT CABLE PLANO HE10 40P
GTIN (EAN)	4008190264703	
Qty.	1 ST	

**Accessories**

Type	FBK 40/250 RK	Version	
Order No.	<a href="#">8216380000</a>		Pre-assembled cable, FBK, FLAT CABLE PLANO HE10 40P
GTIN (EAN)	4008190264680		
Qty.	1 ST		