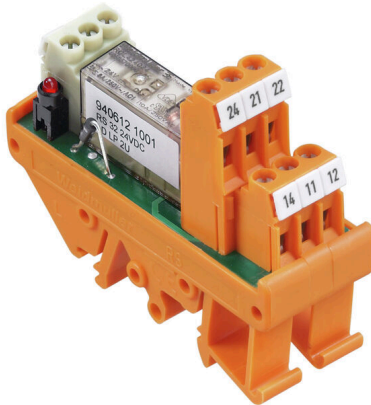


RS 32 24VDC LD LP 2U

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Product image

Similar to Illustration

General ordering data

Version	RS-SERIES, Relay module, Number of contacts: 2, CO contact AgNi 90/10, Rated control voltage: 24 V DC $\pm 10\%$, Continuous current: 4 A, Screw connection
Order No.	8607480000
Type	RS 32 24VDC LD LP 2U
GTIN (EAN)	4032248266982
Qty.	10 items
Delivery status	Discontinued
Available until	2022-11-25T00:00:00+01:00
Alternative product	TRS 24VDC 2CO

RS 32 24VDC LD LP 2U

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS Conform

Dimensions and weights

Net weight 44.26 g

Temperatures

Storage temperature -40 °C...60 °C Operating temperature -25 °C...40 °C

Environmental Product Compliance

RoHS Compliance Status Compliant
 REACH SVHC Lead 7439-92-1
 SCIP 7b5ffb72-271d-4c73-8b09-bd0aaee3697a

Control side

Rated control voltage 24 V DC $\pm 10\%$ Status indicator red LED
 Protective circuit Free-wheeling diode,
 Reverse polarity protection

Load side

Rated switching voltage 250 V AC AC switching capacity (resistive), max. 1000 VA
 Switch-off delay ≤ 10 ms Contact type 2 CO contact (AgNi
 90/10)

General data

Colour orange

Insulation coordination

Rated voltage 300 V Dielectric strength to mounting rail 4 kVeff / 1 Min.
 Impulse withstand voltage 4 kV (1.2/50 μ s) Protection degree IP20

Connection data

Wire connection method Screw connection

Classifications

ETIM 8.0 EC001437 ETIM 9.0 EC001437
 ETIM 10.0 EC001437 ECLASS 14.0 27-37-16-01
 ECLASS 15.0 27-37-16-01