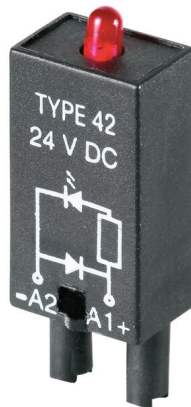


RIM 3 6/24VUC**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Product image**

Similar to illustration

General ordering data

Version	RIDERSERIES RCL, LED module, Rated control voltage: 6...24 V UC, Plug-in connection
Order No.	8691010000
Type	RIM 3 6/24VUC
GTIN (EAN)	4032248361694
Qty.	10 items
Delivery status	This article will no longer be available in the future.
Last order date	2026-03-30T00:00:00+02:00
Alternative product	CXX L 61R

RIM 3 6/24VUC

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate No. (cURus)	E223759

Dimensions and weights

Depth	34.5 mm	Depth (inches)	1.3583 inch
Height	9 mm	Height (inches)	0.3543 inch
Width	12.5 mm	Width (inches)	0.4921 inch
Net weight	2.95 g		

Temperatures

Storage temperature	-40 °C...70 °C	Operating temperature	-40 °C...70 °C
Humidity	40 °C / 93 % rel. humidity, no condensation		

Environmental Product Compliance

RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	7a, 7cl
REACH SVHC	Lead 7439-92-1
SCIP	2f8197d4-bb8c-4bf4-a0f8-f906b0694c85

Rated data UL

Certificate No. (cURus)	E223759
-------------------------	---------

Control side

Rated control voltage	6...24 V UC	Status indicator	red LED
-----------------------	-------------	------------------	---------

General data

Colour	black
--------	-------

Further details of approvals / standards


Standards	UL508	Certificate No. (cURus)	E223759
-----------	-------	-------------------------	---------

Connection data

Wire connection method	Plug-in connection
------------------------	--------------------

Classifications

ETIM 8.0	EC002586	ETIM 9.0	EC002586
ETIM 10.0	EC002586	ECLASS 14.0	27-37-16-92
ECLASS 15.0	27-37-16-92		

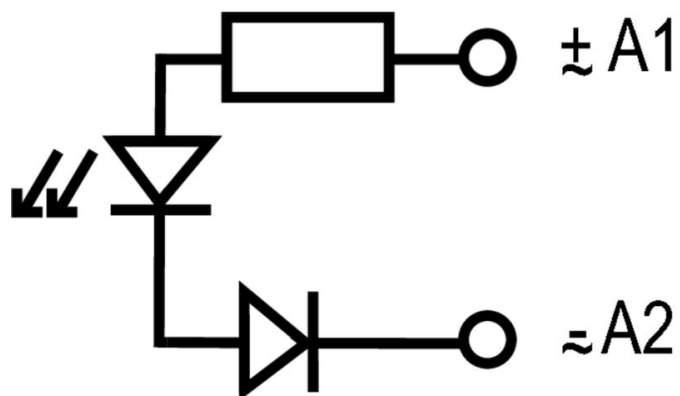Drawings**Wiring diagram****Dimensional drawing**