 


RIM 4 110/230VUC GN

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Product image



General ordering data

Version	RIDERSERIES RCL, LED module, Protective varistor, Rated control voltage: 110...230 V UC, Plug-in connection
Order No.	8713800000
Type	RIM 4 110/230VUC GN
GTIN (EAN)	4032248390182
Qty.	10 items
Delivery status	This article will no longer be available in the future.
Available until	2026-03-30T00:00:00+02:00

RIM 4 110/230VUC GN

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS Conform

UL File Number Search [UL Website](#)

Certificate No. (cURus) E223759

Dimensions and weights

Depth	34.5 mm	Depth (inches)	1.3583 inch
Height	9 mm	Height (inches)	0.3543 inch
Width	12.5 mm	Width (inches)	0.4921 inch
Net weight	2.84 g		

Temperatures

Storage temperature	-40 °C...70 °C	Operating temperature	-40 °C...70 °C
Humidity	40 °C / 93 % rel. humidity, no condensation		

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Rated data UL

Certificate No. (cURus)	E223759
-------------------------	---------

Control side

Rated control voltage	110...230 V UC	Status indicator	Green LED
Protective circuit	Varistor		

General data

Colour	black
--------	-------

Further details of approvals / standards

Standards	UL508	Certificate No. (cURus)	E223759
-----------	-------	-------------------------	---------

Connection data


Wire connection method	Plug-in connection
------------------------	--------------------

Classifications

ETIM 8.0	EC002586	ETIM 9.0	EC002586
ETIM 10.0	EC002586	ECLASS 14.0	27-37-16-92
ECLASS 15.0	27-37-16-92		

Drawings

Wiring diagram

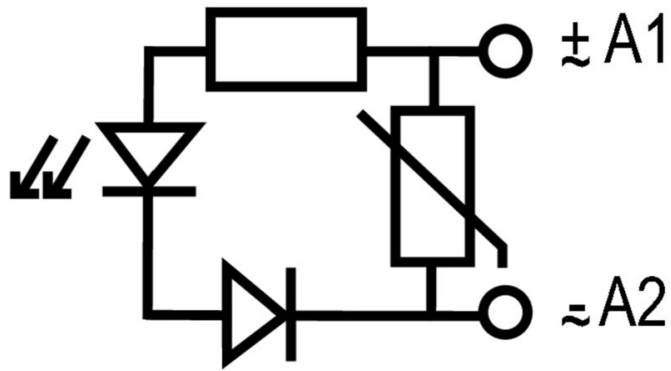

Dimensional drawing

