


## MEHA KP GE M-D-SPX

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

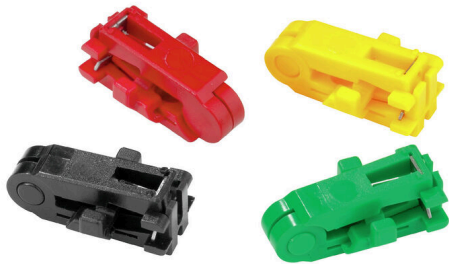

- Flexible and solid wire with PVC, Teflon (PTFE) and silicone insulation
- No damage to the wire thanks to specially shaped blade
- No splicing of individual wires
- Blade inserts are easy to replace
- All inserts fit one housing
- Guide bars in the blade cassettes facilitate correct positioning of the wire in the tool

### General ordering data

Version	Accessories, Set of cutters
Order No.	<a href="#">9003600000</a>
Type	MEHA KP GE M-D-SPX
GTIN (EAN)	4008 190140274
Qty.	1 items

## MEHA KP GE M-D-SPX

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Technical data

### Dimensions and weights

Depth	16 mm	Depth (inches)	0.6299 inch
Height	11.5 mm	Height (inches)	0.4528 inch
Width	26 mm	Width (inches)	1.0236 inch
Length	26 mm	Length (inches)	1.0236 inch
Net weight	3.68 g		

### Environmental Product Compliance

RoHS Compliance Status	Not affected
REACH SVHC	No SVHC above 0.1 wt%

### Technical data

Description of article	Set of blades for Mini-Duro-Stripax up to AWG 30 for PTFE
------------------------	---

### Stripping tools

Cable type	Conductor with custom insulation	Max. conductor diameter	0.3 mm
Min. conductor diameter	0.2 mm	Stripping length, max.	7 mm
Stripping length, min.	3 mm	Colour	yellow

### Classifications

ETIM 8.0	EC001509	ETIM 9.0	EC001509
ETIM 10.0	EC001509	ECLASS 14.0	21-04-48-91
ECLASS 15.0	21-04-48-91		