

M-D-STRIPAX AWG 20+22**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

- Flexible and solid wire with PVC, Teflon (PTFE) and silicone insulation
- No damage to the wire thanks to specially shaped blade
- No splicing of individual wires
- Blade inserts are easy to replace
- All inserts fit one housing
- Guide bars in the blade cassettes facilitate correct positioning of the wire in the tool

General ordering data

Version	Tools, Stripping and cutting tool
Order No.	9003730000
Type	M-D-STRIPAX AWG 20+22
GTIN (EAN)	4008190102012
Qty.	1 items
Delivery status	Discontinued
Available until	2022-03-01T00:00:00+01:00
Alternative product	MEHA KP BL M-D-SPX

M-D-STRIPAX AWG 20+22**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com
Technical data**Dimensions and weights**

Depth	16 mm	Depth (inches)	0.6299 inch
Height	135 mm	Height (inches)	5.3149 inch
Width	82 mm	Width (inches)	3.2283 inch
Net weight	96.28 g		

Environmental Product Compliance

RoHS Compliance Status	Not affected
REACH SVHC	Lead 7439-92-1
SCIP	cf06c250-ed1e-4a45-9c1b-c5c8cbf13bf0

Technical data

Description of article	Stripping tool for up to AWG 20, for PTFE
------------------------	--

Stripping tools

Cable type	Conductor with custom insulation	Max. conductor diameter	0.92 mm
Min. conductor diameter	0.88 mm	Stripping range AWG, max.	20 AWG
Stripping range AWG, min.	20 AWG	Stripping length, max.	7 mm

Classifications

ETIM 8.0	EC002109	ETIM 9.0	EC002109
ETIM 10.0	EC002109	ECLASS 14.0	21-04-37-06
ECLASS 15.0	21-04-37-06		

M-D-STRIPAX AWG 20+22

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

Example of use




M-D-STRIPAX AWG 20+22

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Accessories / replacement parts

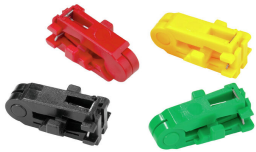

- Flexible and solid wire with PVC, Teflon (PTFE) and silicone insulation
- No damage to the wire thanks to specially shaped blade
- No splicing of individual wires
- Blade inserts are easy to replace
- All inserts fit one housing
- Guide bars in the blade cassettes facilitate correct positioning of the wire in the tool

General ordering data

Type	MEHA KP GE M-D-SPX	Version
Order No.	9003600000	Accessories, Set of cutters
GTIN (EAN)	4008190140274	
Qty.	1 ST	
Type	MEHA KP RT M-D-SPX	Version
Order No.	9003610000	Accessories, Set of cutters
GTIN (EAN)	4008190058272	
Qty.	1 ST	
Type	MEHA KP GN M-D-SPX	Version
Order No.	9003620000	Accessories, Set of cutters
GTIN (EAN)	4008190130527	
Qty.	1 ST	
Type	MEHA KP BL M-D-SPX	Version
Order No.	9003630000	Accessories, Set of cutters
GTIN (EAN)	4008190094256	
Qty.	1 ST	
Type	MEHA KP SW M-D-SPX	Version
Order No.	9003640000	Accessories, Set of cutters
GTIN (EAN)	4008190020507	
Qty.	1 ST	
Type	MEHA KP WS M-D-SPX	Version
Order No.	9006970000	Accessories, Set of cutters
GTIN (EAN)	4032248363711	
Qty.	1 ST	