

## H0,5/14 OR BD


**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

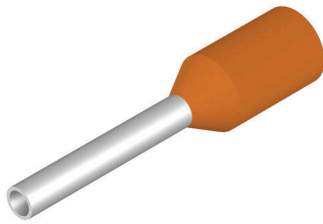

- Linked of wire-end ferrule strips (50 pcs.)
- Weidmüller colour code
- DIN colour code

### General ordering data

Version	Wire-end ferrule, Standard, 10 mm, 8 mm, orange
Order No.	<a href="#">9004270000</a>
Type	H0,5/14 OR BD
GTIN (EAN)	4008 19009 1774
Qty.	500 items
Packaging	Reel packaged

**Technical data**

**Approvals**

Approvals



ROHS	Conform
UL File Number Search	<a href="#">UL Website</a>
Certificate no. (cULus)	E499744

**Dimensions and weights**

Net weight	0.07 g
------------	--------

**Environmental Product Compliance**

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

**Technical data**

Description of article	Strip of wire end ferrules, orange	Version	Standard
------------------------	------------------------------------	---------	----------

**Wire-end ferrules**

Contact surface diameter (D1)	1 mm	Contact surface length (L2)	8 mm
Collar diameter (D2)	2.6 mm	Plastic collar thickness (S2)	0.25 mm
L1 in mm	14.00 mm	Wire connection cross section AWG, max.	AWG 20
Metal sleeve thickness (S1)	0.15 mm	Stripping length	10 mm
Conductor cross-section	0.5 mm <sup>2</sup>	Colour code	Weidmueller

**Classifications**

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

