


H0,75/14T HBL BD

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

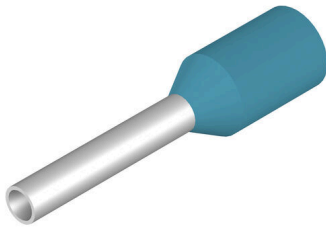

- Linked of wire-end ferrule strips (50 pcs.)
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

| | |
|------------|---|
| Version | Wire-end ferrule, Standard, 10 mm, 8 mm, Light Blue |
| Order No. | 9004310000 |
| Type | H0,75/14T HBL BD |
| GTIN (EAN) | 4008 1901 79298 |
| Qty. | 500 items |
| Packaging | Reel packaged |

H0,75/14T HBL BD

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS Conform

UL File Number Search [UL Website](#)

Certificate no. (cULus) E499744

Dimensions and weights

Net weight 0.08 g

Environmental Product Compliance

RoHS Compliance Status Compliant without exemption

REACH SVHC No SVHC above 0.1 wt%

Technical data

| Description of article | Strip of wire end ferrules, light blue | Version | Standard |
|------------------------|---|---------|----------|
|------------------------|---|---------|----------|

Wire-end ferrules

| | | | |
|-------------------------------|----------------------|--|---------------|
| Contact surface diameter (D1) | 1.2 mm | Contact surface length (L2) | 8 mm |
| Collar diameter (D2) | 2.8 mm | Plastic collar thickness (S2) | 0.25 mm |
| L1 in mm | 14.00 mm | Wire connection cross section AWG, max. | AWG 18 |
| Metal sleeve thickness (S1) | 0.15 mm | Stripping length | 10 mm |
| Conductor cross-section | 0.75 mm ² | Colour code | Telemecanique |

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 8.0 | EC000005 | ETIM 9.0 | EC000005 |
| ETIM 10.0 | EC000005 | ECLASS 14.0 | 27-40-02-01 |
| ECLASS 15.0 | 27-40-02-01 | | |

Drawing

