


## H2,5/14D BL BD

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

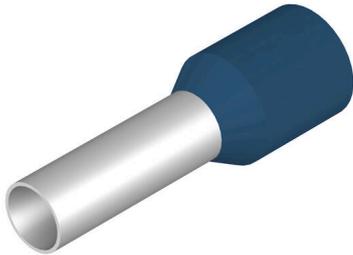

- Linked of wire-end ferrule strips (50 pcs.)
- DIN colour code
- other colour code

### General ordering data

Version	Wire-end ferrule, Standard, 12 mm, 8 mm, blue
Order No.	<a href="#">9004360000</a>
Type	H2,5/14D BL BD
GTIN (EAN)	4008 190083397
Qty.	500 items
Packaging	Reel packaged

**Technical data**

**Approvals**

Approvals



ROHS	Conform
UL File Number Search	<a href="#">UL Website</a>
Certificate no. (cULus)	E499744

**Dimensions and weights**

Net weight	0.12 g
------------	--------

**Environmental Product Compliance**

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

**Technical data**

Description of article	Linked wire-end ferrules, blue	Version	Standard
------------------------	--------------------------------	---------	----------

**Wire-end ferrules**

Contact surface diameter (D1)	2.2 mm	Contact surface length (L2)	8 mm
Collar diameter (D2)	4.2 mm	Plastic collar thickness (S2)	0.25 mm
L1 in mm	14.00 mm	Wire connection cross section AWG, max.	AWG 14
Metal sleeve thickness (S1)	0.15 mm	Military designation	T 20A 017 A
Stripping length	12 mm	Conductor cross-section	2.5 mm <sup>2</sup>
Colour code	DIN		

**Classifications**

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

