


## H2,5/19D ZH BL SV

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

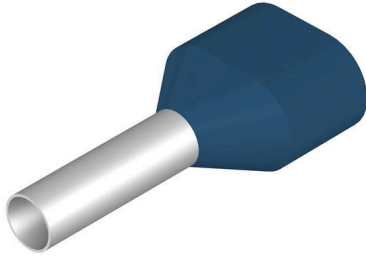

- in multi-pack bag (5 x 100 pcs.)
- DIN colour code
- other colour code

### General ordering data

Version	Wire-end ferrule, Twin wire-end ferrule, 13 mm, 10 mm, blue
Order No.	<a href="#">9004430000</a>
Type	H2,5/19D ZH BL SV
GTIN (EAN)	4008 190099367
Qty.	250 items
Packaging	Multipack bag

## H2,5/19D ZH BL SV

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Technical data

### Approvals

Approvals



ROHS Conform

UL File Number Search [UL Website](#)

Certificate no. (cULus) E499744

### Dimensions and weights

Net weight 0.33 g

### Environmental Product Compliance

RoHS Compliance Status Compliant without exemption

REACH SVHC No SVHC above 0.1 wt%

### Technical data

Description of article	Twin wire end ferrule, blue	Version	Twin wire-end ferrule
------------------------	-----------------------------	---------	-----------------------

### Wire-end ferrules

Contact surface diameter (D1)	2.8 mm	Contact surface length (L2)	10 mm
Collar width (B)	4.5 mm	Collar height (A)	8 mm
Plastic collar thickness (S2)	0.4 mm	L1 in mm	19.00 mm
Wire connection cross section AWG, max.	AWG 14	Metal sleeve thickness (S1)	0.15 mm
Stripping length	13 mm	Conductor cross-section	2.5 mm <sup>2</sup>
Colour code	DIN		

### Classifications

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

