


## H6,0/23D ZH GE SV

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

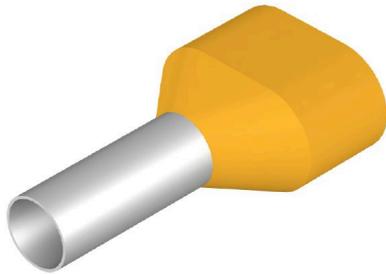

- in multi-pack bag (5 x 100 pcs.)
- Weidmüller colour code
- DIN colour code
- other colour code

### General ordering data

Version	Wire-end ferrule, Twin wire-end ferrule, 20 mm, 12 mm, yellow
Order No.	<a href="#">9004720000</a>
Type	H6,0/23D ZH GE SV
GTIN (EAN)	4008 190962210
Qty.	100 items
Packaging	Multipack bag

**Technical data**

**Approvals**

Approvals



ROHS	Conform
UL File Number Search	<a href="#">UL Website</a>
Certificate no. (cULus)	E499744

**Dimensions and weights**

Net weight	0.7 g
------------	-------

**Environmental Product Compliance**

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

**Technical data**

Description of article	Twin wire end ferrule, yellow	Version	Twin wire-end ferrule
------------------------	-------------------------------	---------	-----------------------

**Wire-end ferrules**

Contact surface diameter (D1)	4.5 mm	Contact surface length (L2)	12 mm
Collar width (B)	6.2 mm	Collar height (A)	11.4 mm
Plastic collar thickness (S2)	0.5 mm	L1 in mm	23.00 mm
Wire connection cross section AWG, max.	AWG 10	Metal sleeve thickness (S1)	0.2 mm
Stripping length	20 mm	Conductor cross-section	6 mm <sup>2</sup>
Colour code	DIN		

**Classifications**

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

**Drawing**

